




TAH1949M

Flare Nut Wrenches with Safety Spring



PRODUCT DETAILS

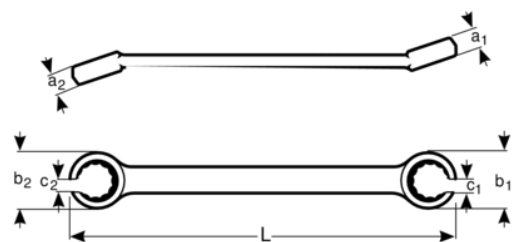

- Double end offset in metric sizes
- Special deep head to protect and apply heavy torque to the screw
- Applications for tube tightening in auto and plumbing environments
- 6 points: 8 x 9, 10 x 11, 10 x 12, 12 x 13 and 12 x 14
- 12 points: 14 x 15 and 14 x 17 onwards
- Chrome micro-matte finishing provides high quality surface
- High-performance alloy steel
- Standards: DIN 3118
- Suitable for working at height
- Permanent stainless steel sliding spring maintains user ergonomics and full functionality
- Colour plates with maximum weight for a right matching with the lanyard
- According to DROPS best practices



Follow the Fish!



PRODUCT ATTRIBUTES

Product		L	a1	a2	b1	b2	c1	c2	
TAH1949M-8-9	8x9 mm	140 mm	7 mm	8 mm	18 mm	20 mm	6 mm	6,5 mm	50 g
TAH1949M-10-11	10x11 mm	150 mm	8,5 mm	9 mm	20 mm	22 mm	7 mm	8,5 mm	70 g
TAH1949M-12-14	12x14 mm	170 mm	9,5 mm	11 mm	24 mm	28 mm	9 mm	11 mm	95 g
TAH1949M-14-17	14x17 mm	200 mm	11 mm	12 mm	28 mm	30 mm	11 mm	14 mm	135 g
TAH1949M-19-22	19x22 mm	220 mm	13,5 mm	15,5 mm	34 mm	40 mm	15 mm	17 mm	215 g
TAH1949M-24-27	24x27 mm	255 mm	16,5 mm	17,5 mm	44,5 mm	47,5 mm	18 mm	20 mm	335 g

Follow the Fish!



Contact: info@bahco.com / www.bahco.com