


Part Number: [0982660167](#)
Status: Active
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Tin (Sn) Plating, 16 Circuits

Documents:	
図面 (PDF)	Datasheet (PDF)
製品仕様書 PS-98266-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
梱包仕様書 PK-98266-001-001 (PDF)	

一般 コメント	Contacts on the same side, Type A
Crimp Quality Equipment 概要	Yes FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
製品名 UPC	Premo-Flex FFC Jumper 756054768006
機械的性能/材質 ケーブル長	102.00mm
極数 (実装)	16
Contact Layout Type	A (same side)
材質 - 嵌合部メッキ	錫
Net Weight	0.542/g
梱包形態	ポリ袋
ピッチ - 嵌合部 (インチ)	0.50mm
使用温度範囲	-40° to +105° C
電線サイズ (AWG)	N/A
ケーブル種別	FFC
電気的性能 最大定格電流	0.5A
最大定格電圧	60V AC
Solder Process Data Lead-freeProcess Capability	N/A
参考情報	
図面・仕様書情報	
梱包仕様書	PK-98266-001-001
製品仕様書	PS-98266-001-001
製品図面	SD-98266-001

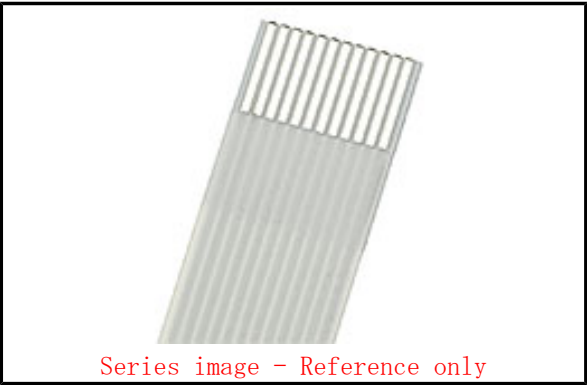

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - ED/108/2014 (17 Dec 2014)	
Halogen-Free Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS ELV	Green Image Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series 98266 Series
Mates With Easy-On FFC/FPC Connector: 527451633 , 527461633 , 525591633 , 525591634