

# BUMPER

## D-Type Bumper Stop 65L x 33W x 22H

SKU.: 0734086




### Features

- **Easy installation**  
– on a variety of surfaces
- **Essential accessory**– For commercial and industrial environments
- **Superior impact absorption** – to reduce risk of damage



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

# BUMPER

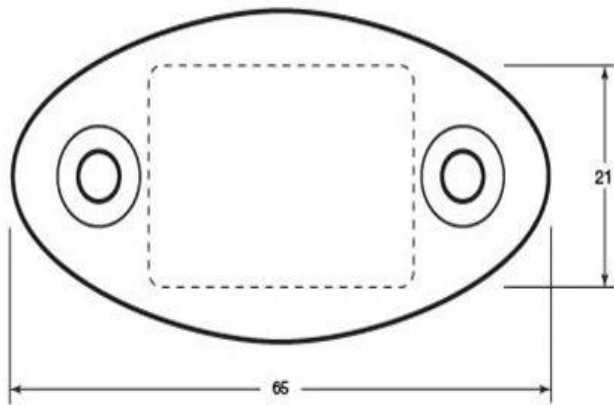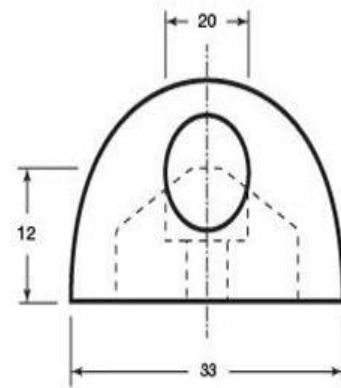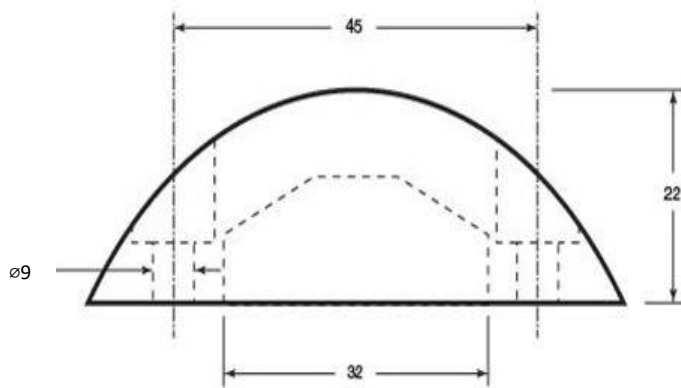

## Bumper Dimensions

Length (mm)	65
Width (mm)	33
Height (mm)	22

# BUMPER

## Product Description

Oval Rubber Bumper Stops are designed to provide exceptional protection for vehicles and properties. These reliable rubber buffers are easy to install and can be fixed securely on a variety of surfaces, making them a versatile choice for any setting. Manufactured from strong SBR rubber, these heavy-duty rubber buffers are built to withstand harsh conditions, ensuring long-lasting performance. Our range includes conical rubber buffers, round rubber buffers, and rubber fenders, catering to different needs and applications.

Whether you are looking for rubber buffer stops for crane operations or robust rubber bumpers for loading bays, our products deliver superior impact absorption and durability. The design of these dock bumpers ensures they effectively reduce the risk of damage to both vehicles and structures, making them an essential accessory for any commercial or industrial environment.

## General Specifications

<b>Material</b>	NR/SBR
<b>Colour</b>	Black

## Mechanical Specifications

<b>Weight</b>	0.022KG
<b>Tensile Strength</b>	4Mpa
<b>Elongation</b>	200%
<b>Hardness</b>	75ShA

## Operation Environment Specifications

<b>Maximum Temperature</b>	70°C
<b>Minimum Temperature</b>	-15°C