




Telephone +44 (0) 121 789 8686  
 Fax (Sales) +44 (0) 121 789 8778  
 Fax (Admin) +44 (0) 121 789 9696

sales@ablcomponents.co.uk

## PPD0380P

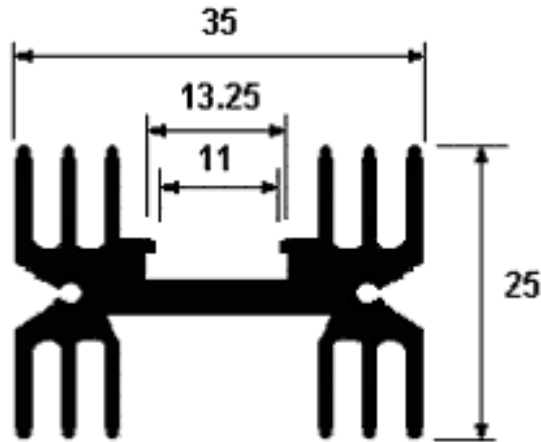

Length	Part Number Without Pins	Part Number With Pins	Holes	Clip	Thermal Rating °C/W	Stock Category
25.0	PPD25B	PPD25BP	No	03	9.00	A
25.0	PPD25BH	PPD25BPH	Yes	03	9.00	A
38.0	PPD38P	PPD38BP	No	03	7.00	A
38.0	PPD38BH	PPD38BPH	Yes	03	7.00	A
50.0	PPD50B	PPD50BP	No	03	5.50	A
50.0	PPD50BH	PPD50BPH	Yes	03	5.50	A
63.0	PPD63B	PPD63BP	No	03	4.50	A
63.0	PPD63BH	PPD63BPH	Yes	03	4.50	A

Thermal Resistance is calculated based on a distributed heat load and vertically mounted fins anodised heatsink with a 60°C temperature. Under general operating conditions the thermal mounting arrangement of devices is not known and therefore the figures should be used only as a guide to selection. We recommend that the effectiveness of any heatsink is tested in the specific operating environment in which it will be subjected. Drawing above is for illustration purposes only. If any further information is required please contact us.