



**GDM 2014 J**

932 107-100

200 Stück each pièces



**GDM 3009**

931 969-100  
931 969-106

 
200 Stück each pièces



**GDM 3009 J**

932 214-100  
932 214-106





200 Stück each pièces



**GDM 3011**

931 952-100  
931 952-106

200 Stück each pièces

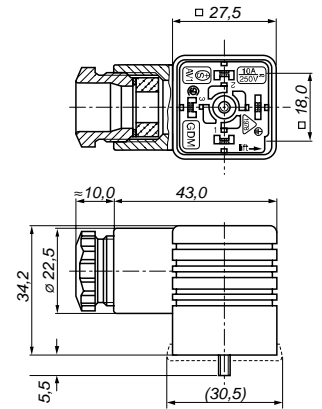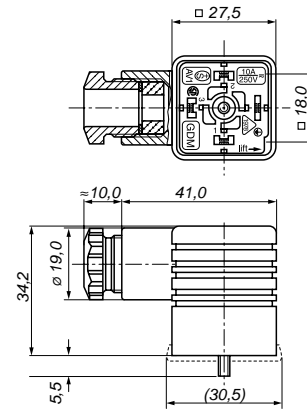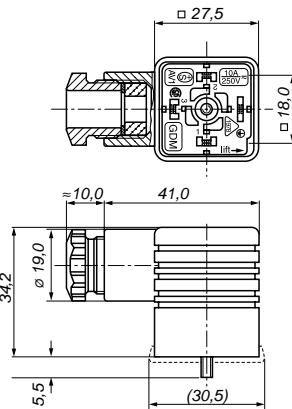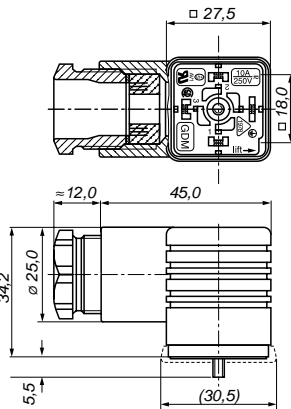

2 + ⊕

**DIN 43 650-A**

3 + ⊕

**DIN 43 650-A**

3 + ⊕

**DIN 43 650-A**

3 + ⊕

**DIN 43 650-A**

**Leitungsdose mit Zentral-  
schraube M 3 x 35**  
cable socket with central screw  
M 3 x 35  
*prise secteur avec vis centrale  
M 3 x 35*

**Leitungsdose mit Zentral-  
schraube M 3 x 35**  
cable socket with central screw  
M 3 x 35  
*prise secteur avec vis centrale  
M 3 x 35*

**Leitungsdose mit Zentral-  
schraube M 3 x 35**  
cable socket with central screw  
M 3 x 35  
*prise secteur avec vis centrale  
M 3 x 35*

**Leitungsdose mit Zentral-  
schraube M 3 x 35**  
cable socket with central screw  
M 3 x 35  
*prise secteur avec vis centrale  
M 3 x 35*

Seite Page Page 10  
**UC 250 V (≈)**  
3  
16 A  
-40 °C ... +125 °C

**ISO 228 - G<sup>1</sup>/<sub>2</sub> (R<sup>1</sup>/<sub>2</sub>" )**  
ø 6 ... 13 mm  
**Schrauben/Kabelschuh/Ringöse**  
screw/cable shoe/cable eye  
*visser/cosse à oeillet/cosse à  
fourche*

Seite Page Page 10  
**UC 250 V (≈)**  
3  
16 A  
-40 °C ... +125 °C

**Pg 9**  
ø 4,5 ... 7 mm  
**Schrauben screw visser**

Seite Page Page 10  
**UC 250 V (≈)**  
3  
16 A  
-40 °C ... +125 °C

**Pg 9**  
ø 4,5 ... 7 mm  
**Schrauben/Kabelschuh/Ringöse**  
screw/cable shoe/cable eye  
*visser/cosse à oeillet/cosse à  
fourche*

Seite Page Page 10  
**UC 250 V (≈)**  
3  
16 A  
-40 °C ... +125 °C

**Pg 11**  
ø 6 ... 9 mm  
**Schrauben screw visser**

GDM 3-7 730 801-002  
GDM 3-21 731 739-002  
GDM 3-16 731 531-002  
GDM 3011-8 732 574-001  
GDM 3011 RF-1 734 363-001

GDM 3-7 730 801-002  
GDM 3-21 731 739-002  
GDM 3-16 731 531-002  
GDM 3011-8 732 574-001  
GDM 3011 RF-1 734 363-001

GDM 3-7 730 801-002  
GDM 3-21 731 739-002  
GDM 3-16 731 531-002  
GDM 3011-8 732 574-001  
GDM 3011 RF-1 734 363-001

GDM 3-7 730 801-002  
GDM 3-21 731 739-002  
GDM 3-16 731 531-002  
GDM 3011-8 732 574-001  
GDM 3011 RF-1 734 363-001