




Technical data

KH4060
Ball sleeves

VISUAL (S)

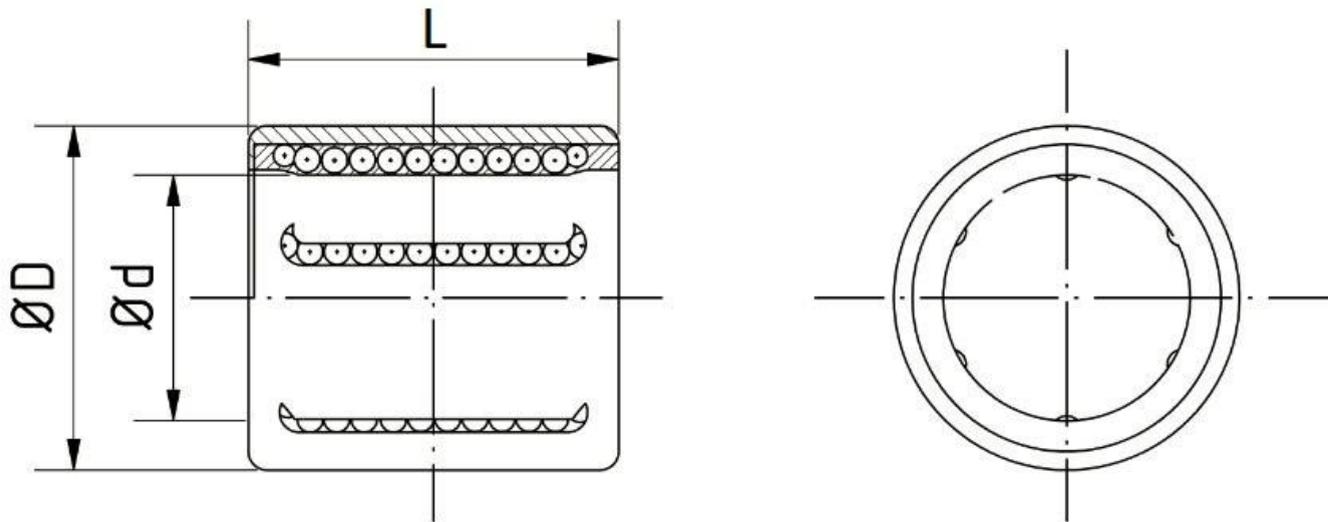

PRODUCT DEFINITION

Brand	NTN
Design type	KH
Ball bushings category	Ball sleeves
Standard	ISO dimension
Material outer cylinder or steel segments	hardened steel sleeve
Material Cage	PA
Initial greasing	Non/No
Re-lubricable	Oui/Yes
d - Internal diameter	40 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

D - External diameter	52 mm
L - Length	60 mm
Number of ball rows	8
Mass	0,18 kg

PRODUCT PERFORMANCE

Cmin	4250000 mN
Cmax	4250000 mN
C0min	4000000 mN
C0max	4000000 mN
Tmin - Min operating temperature	253,15 °K
Tmax - Max operating temperature	353,15 °K

