
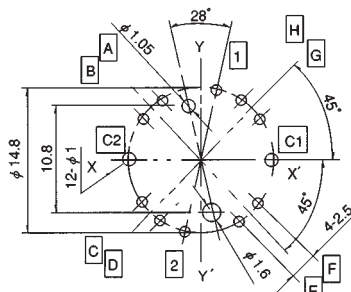
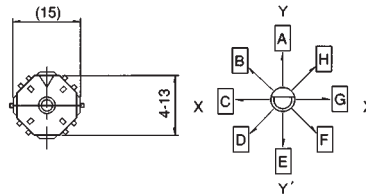


Compact Stick Switch


Order Number	Model	Switch ratings	Contact resistance lever/ push operation	Insulation resistance	Voltage proof	Operating life
STRKJXL01	RKJXL	DC 5V 10mA	500m/500m Ω max.	100M Ω min. at 250V DC	300V AC for 1 minute	100,000 cycles

Features: 8 - direction switcher with push-on selector sw
(Version without push-on switch is also available)

RKJXL

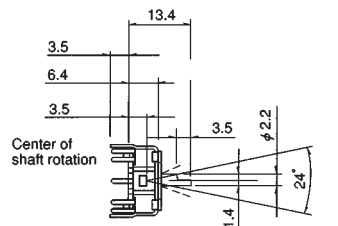

Mounting hole details
Viewed from mounting side

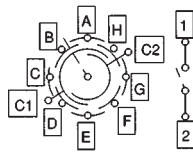

SW
Circuit

The following terminals conduct according to the operational direction of the shaft.
(Adjoining terminals have a shorting zone)



Push On



(C1) and (C2) conduct between (H)-(A) and (D)-(E).
(1)-(2) conduct by push-on operation.

Unit: (mm)