


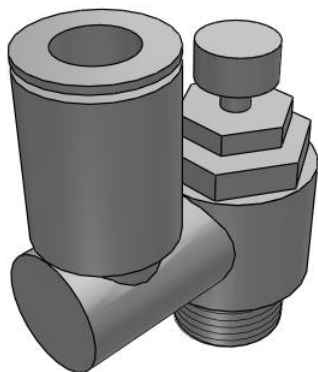

Universal - AS*3*1F AS3301F-03-10S

Datasheet


General series information

- Port Size: M3, M5, 10-32 UNF, 1/8, 1/4, 3/8, 1/2
- Applicable Tubing O.D.: Ø 3.2 to Ø 12 mm and Ø 1/8" to Ø 1/2"
- Operating Pressure Range: 0.1 to 1 MPa.

Standard specifications

Size	3 (3/8 Basis)
Style	3 (Universal)
Control Method	0 (Meter-out)
Thread	M3, M5, U10/32, Rc
Port Size	03 (3/8)
Tube Size	Ø10
Option	S (Sealant)
Fixed Orifice	None
Made to Order	None
Lock Nut	Standard (Hexagon)
Weight	0.063 Kg

Dimensions

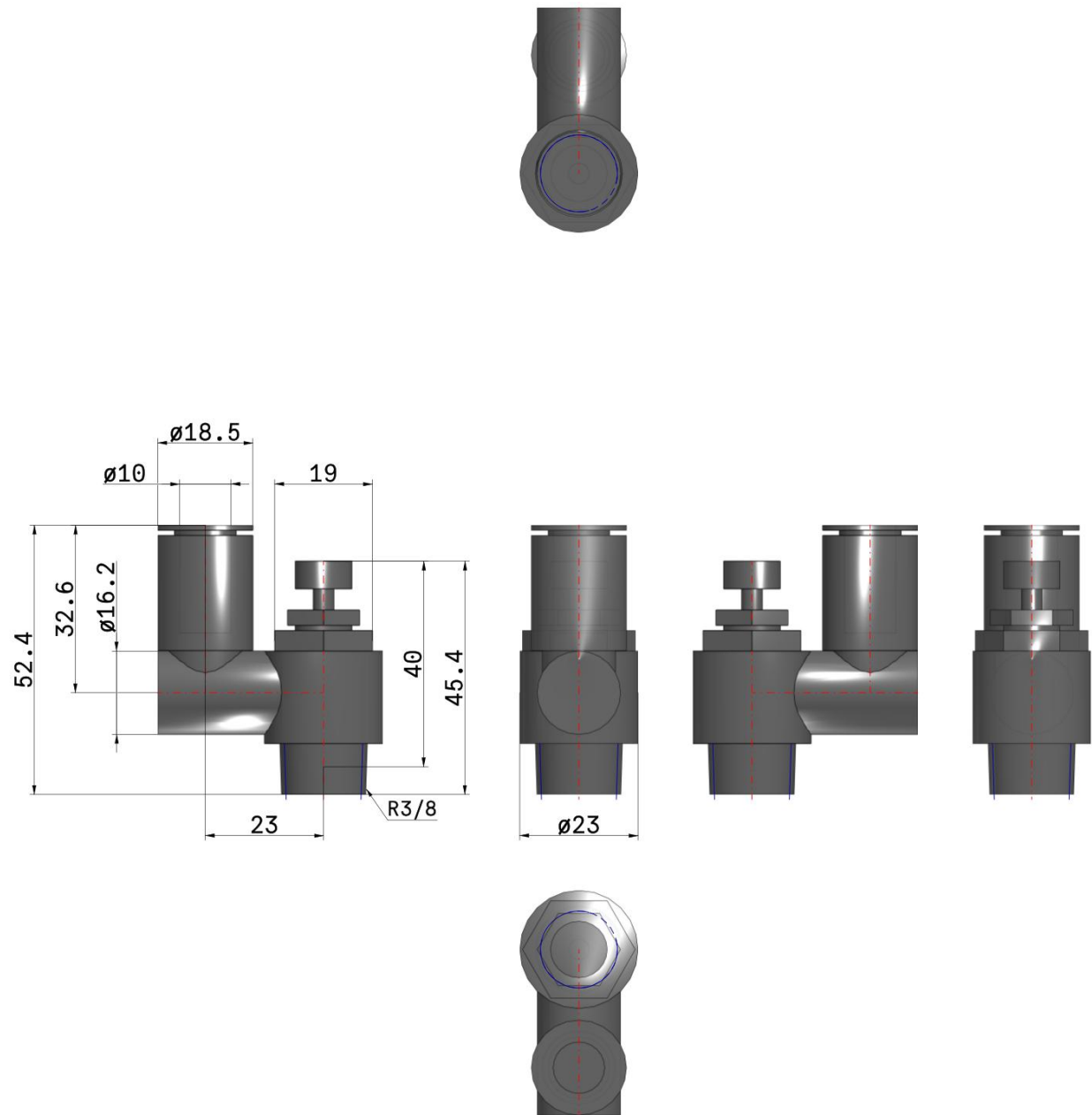

Additional information

Catalogue

[AS_2-3_1F-A_EU.pdf](#)