


Pin spacing: 3.5 mm / 0.138 in.


0.5 ... 1.5 mm² "sol." | 20 ... 16 AWG "sol."
 320 V/4 kV/2 2 A | 300 V/2 A

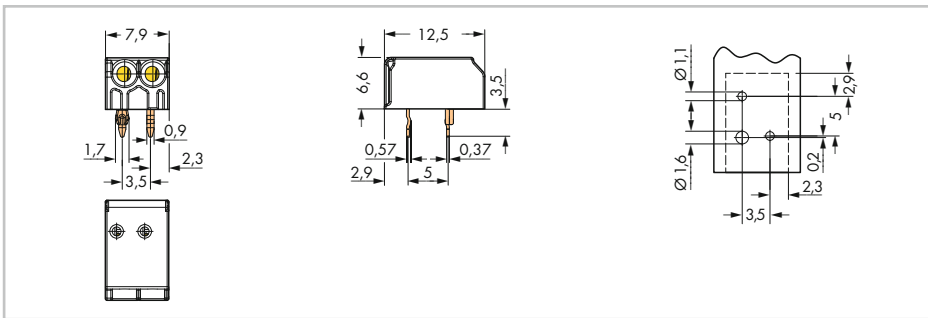

2-pole version with additional anti-rotating pin



Inserting solid conductor via push-in termination.

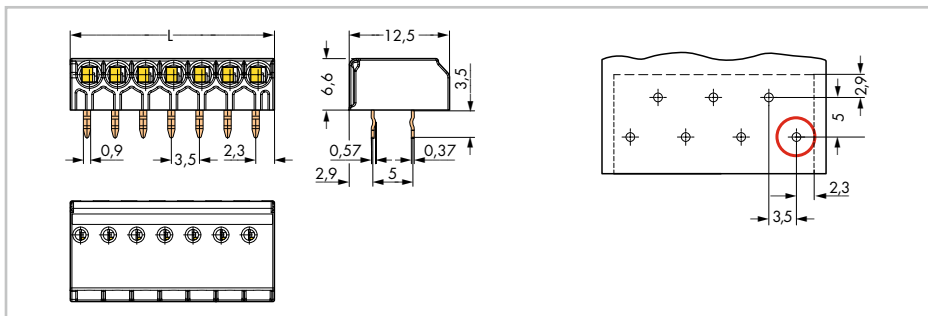

For 3 poles and more, L = (pole no. x pin spacing) + 0.9 mm
 ○ first solder pin, right front side



Removing conductor via 1.0 mm Ø disconnection tool. (206-841)

Pole No.	Item No.	Pack. Unit
PCB terminal block with disconnecting slots, white		
2	744-392	1500
3	744-303	1000
4	744-304	800
6	744-306	500
7	744-307	300
8	744-308	300
10	744-310	200