


## Wirable socket

SDOGF040MSSFPKG

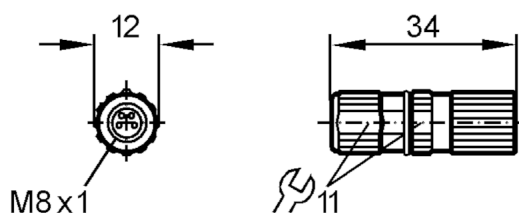

## Application

Special feature

Gold-plated contacts

## Electrical data

Operating voltage

[V]

&lt; 45 AC / &lt; 70 DC

Protection class

III

Max. current load total

[A]

4

## Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 68

## Mechanical data

Weight

[g]

17.1

Materials

Core insulation: PVC / TPE

Moulded-body material

PA

Material nut

brass, nickel-plated

## Remarks

Pack quantity

1 pcs.

# E11553



## Wirable socket

SDOGF040MSSFPKG

### Electrical connection

insulation displacement technology: 0.14...0.38 mm<sup>2</sup>; Core insulation: PVC / TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



### Connection

