


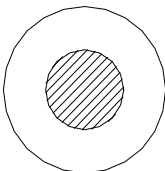

Datasheet

Product Name:	UL1213 26AWG
Product Discription:	UL1213 26AWG
Specification No.:	
Customer's Name:	

Description					Construction						
Rated Voltage:		Not specified			Conductor		Stranded Sliver plated copper				
Rated Temperature:		105℃, 60℃ Oil			Size(AWG)		26				
Reference Standard:		UL758			Construction(±0.008mm)		7/0.16				
Cross Section					Stranded Dia.(mm)Ref.		0.48				
					Insulation Material		PTFE				
					Insulation Color		ANY COLOR				
					Ave Thickness(mm)		0.2				
					Insulation Dia.(±0.08mm)		0.97				
Marking					Remark:						
No marking on the cable jacket, have UL label on the Reel.					8739661 Red		8739664 Blue		8739683 Grey	8739686 Violet	
					8739658 Black		8739668 White		8739670 Yellow		
					8739652 Brown		8739677 Green		8739674 Orange		
Applications					Characteristics				Customer Approve		
Internal wiring where not subjected to mechanical abuse, Oil Resistant 60 deg C.					Test Item		Standard Value			Seal & Stamp	
					Test Material		PTFE(ROHS)				
					Insulation resistance(20℃ MΩ*m		1000				
					Vol. Tesr(AC.V.60S) (V)		2000				
					Flammability Test		Horizontal flame				
Revisions					Max.DC Resistance(20℃ Ω/km)		127(MAX)			Signature: Date:	
Version	Description	Drawn by	Approved by	Date							
0	New document issue	Danniel	Jason	24/04/2015							