




- **OT 12/230-240/10** • **OT 20/230-240/24**
- With integrated cable clamp
- Suitable for separate installation

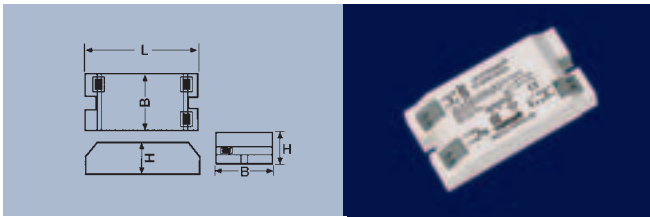


- **OT 8/200-240/24**
- In an extremely compact package for installation in luminaires

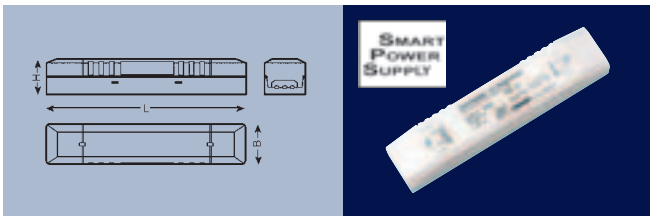

- **OT 50/220-240/10** • **OT 75/220-240/24**
- With integrated cable clamp
- Suitable for separate installation

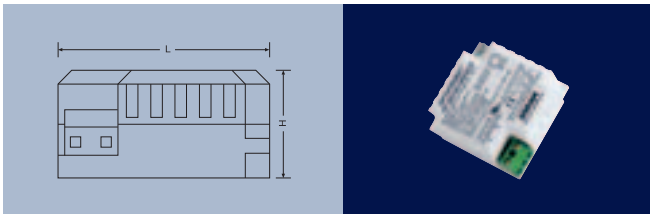

- **OT 20/120-240/24 S**
- The square design is optimized for compact luminaire designs

Product reference	Product number		V min-max	Hz	W MODULE	°C min-max	LxWxH [mm]
<b>OPTOTRONIC® control gear for LEDs</b>							
OT 8/200-240/24	4008321040169	24 V LED module	180–254	0/50/60	8	-20...+50	80 x 40 x 22
OT 12/230-240/10	4050300609232	10 V LED module	207–254	0/50/60	12	-20...+50	109 x 50 x 35
OT 20/230-240/24	4050300618111	24 V LED module	207–254	0/50/60	20	-20...+45	109 x 50 x 35
OT 20/120-240/24 S	4050300662626	24 V LED module	108–254	0/50/60	20	-20...+50	60 x 60 x 31
OT 50/220-240/10	4050300817491	10 V LED module	198–254	0/50/60	50	-20...+50	220 x 47 x 44
OT 75/220-240/24	4050300817477	24 V LED module	198–254	0/50/60	75	-20...+50	220 x 47 x 44