



## U-Kühlkörper

## U-shaped Heatsinks

## Dissipateurs en U

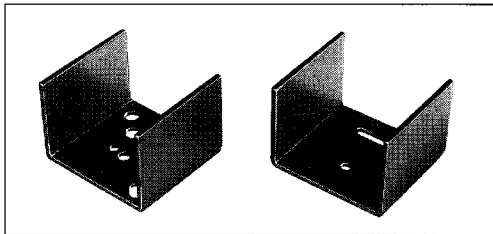


**UK 35** RS 189-8038 + RS 189-8044  
11 K/W

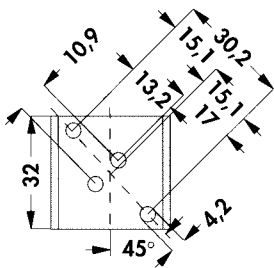


**UK 35/SA-3**  
**UK 35/AL-3**

TO 3

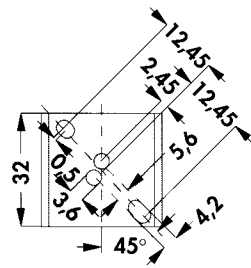


**UK 35/SA 9-66**  
**UK 35/AL 9-66**

SOT 9 - TO 66

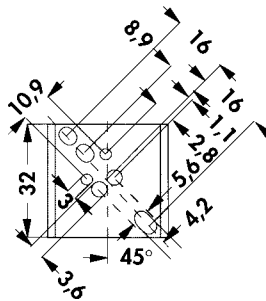


**UK 35/SA-CB**  
**UK 35/AL-CB**

CB (TO 3 SOT 9 - TO 66)

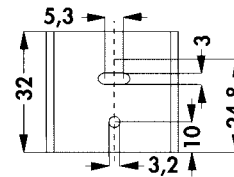

**UK 35/SA-32**  
**UK 35/AL-32**

SOT 32

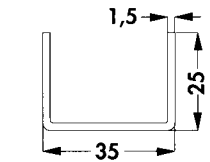



**UK 35/SA-220**  
**UK 35/AL-220**

TO 220


**ICK 35/SA**

15 K/W

TO 220

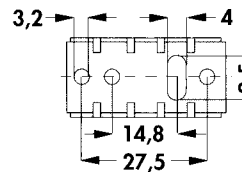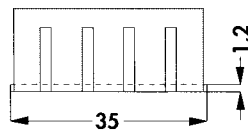

RS 189-9031


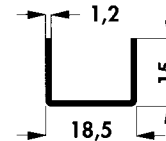


RS 191-0374


**UK 14/SA**

20 K/W

TO 220

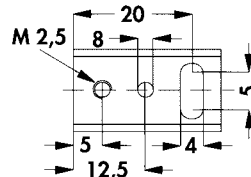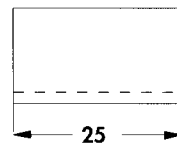

RS 189-8577

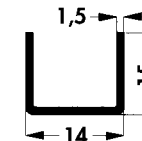

RS 189-8583



**SK 12**

25 mm 30 K/W

50 mm 15 K/W

1 x SOT 32



2 x SOT 32

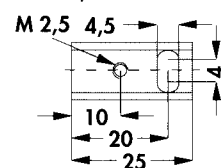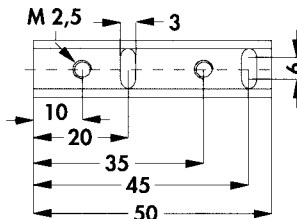

**SK 13**

35 mm 17 K/W

TO 220

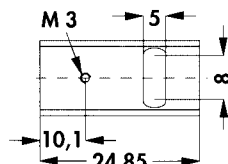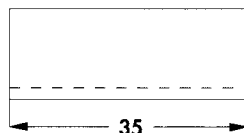

- auch in 2 mm Wandstärke lieferbar.

- thickness of 2 mm also available.

- livrable aussi en 2 mm d'épaisseur.

**SK 37**

14 K/W



Kühlkörper für Zenerdioden und Thyristoren im Gehäuse DO.

Heatsinks for Zener diodes and thyristors in case DO.

Dissipateurs pour diode Zener et thyristors en boîtier DO.