

Features

- D25 Female
- D25 Female
- All Pins Connected

RS PRO D25 (F) to D25 (F) Slimline Gender Changer

RS Stock No.: 0839477



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

D25 female to female slimline gender changer allows you to change the gender from a male to a female port.

General Specifications

Accessory Type	Gender Changer
For Use With	25 Way D Connector
Gender	Female / Female
Number Of Contacts	25
Colour	Silver / Yellow
Application	Communications ports, Network ports, Computer video output, Game controller ports
Finish	Nickel
Thread Size	#4-40 UNC
Locking Mechanism	Screws
Termination	Plug In

Electrical Specifications



 
Current Rating	5A
----------------	----

Approvals

Standards Met	CE UKCA REACH ROHS
---------------	--------------------

Other Products in This Range

Stock No.	Brand	Type	Connector A	Connector B
0839476	RS PRO	Adapter	D25 (M)	D25 (M)
0839477	RS PRO	Adapter	D25 (F)	D25 (F)
AD-111	RS PRO	Adapter	D15 (M)	D15 (M)
AD-112	RS PRO	Adapter	D15 (F)	D15 (F)
AD-401	RS PRO	Serial Adapter	D9 (F)	D25 (M)
AD-402	RS PRO	Serial Adapter	D9 (F)	D25 (F)
AD-403	RS PRO	Serial Adapter	D9 (M)	to D25 (M)
AD-404	RS PRO	Serial Adapter	D9 (M)	D25 (F)
0839422	RS PRO	VGA Adapter	D9 (M)	HD15 (F)
0839423	RS PRO	VGA Adapter	D9 (F)	HD15 (M)
AD-425	RS PRO	VGA Leaded Adapter	D9 (F)	HD15 (M)
AD-426	RS PRO	VGA Leaded Adapter	D9 (M)	HD15 (F)
0839424	RS PRO	Port Saver	D25 (M)	D25 (F)
0839425	RS PRO	Null Modem Adapter	D25 (M)	D25 (F)
0839427	RS PRO	Port Saver	D9 (M)	D9 (F)
AD-666	RS PRO	Port Saver	HD15 (M)	HD15 (F)

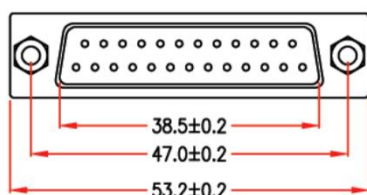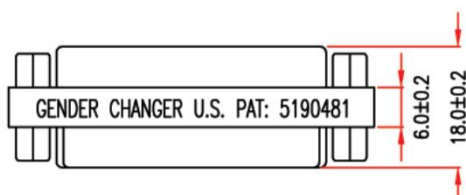

SPECIFICATION:

1. VOLTAGE RATING: 300V AG(rms).
2. CURRENT RATING: 5 AMP CONTINUOUS
3. DIELECTRIC STRENGTH 1000VAG
4. CONTACT RESISTANCE: 10 m Ohm min
5. INSULATION RESISTANCE: 5000 M Ohm min
6. DURABILITY: 30 CYCLEES FOR GOL FLASH
150 CYCLES FOR 15u" COLD PLATED
7. CORROSION RESISATANCE: MEET M-STD-202F METHOD
101 CONITION BSALT WATER
SPRAY OR GOLD PLATED OVER 15u"
- 8.MATING FORCE INSERTION FORCE: 0Z-16 OZ
AVERAGE 150 GRAM
EXTRACTION FORCE: 1KG MIN