 



# air reservoir CRVZS-20

Part number: 534845

**FESTO**

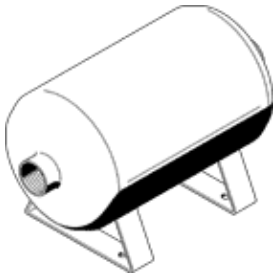

## Data sheet

Feature	Value
Volume	20 l
Assembly position	Downward condensate drain
Conforms to standard	AD 2000 reference sheet
Operating pressure	-0.95 ... 16 bar
Certificate issuing department	CRN0H15669.5C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [:-:-] Nitrogen
CE mark (see declaration of conformity)	to EU directive pressure devices
Corrosion resistance classification CRC	3 - High corrosion stress
Food-safe	See Supplementary material information
Medium temperature	-10 ... 100 °C
Ambient temperature	-10 ... 100 °C
Authorisation	CRN TÜV
Max. tightening torque, connecting thread	130 Nm
Max. tightening torque, condensate drain	27 Nm
Product weight	10,208 g
Mounting type	with through hole
Condensate drain connection	G3/8
Pneumatic connection	G1
Materials note	Free of copper and PTFE Conforms to RoHS
Material of air reservoir	High alloy steel, non-corrosive