



Datasheet

ENGLISH

Stock No: 486-031

RS Pro Black Nitrile Rubber Tank Insulation, 20000mm x 500mm x 9mm

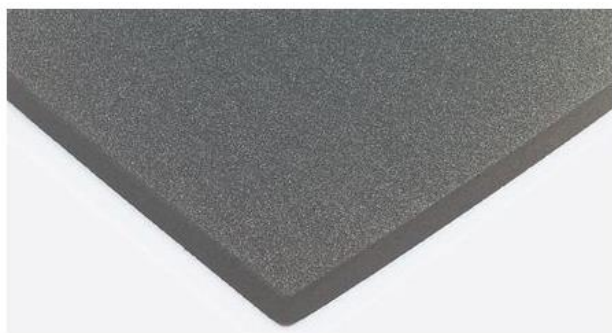


Image representative of range

Product Details

Insulation Sheet Class 0

Fully flexible sheet

Especially suitable for larger areas such as storage tanks, grouped pipework, ducting, and areas with difficult access

Available in 2 metre sheets or roll lengths

Temperature range from -40°C to +116°C (when adhered to a flat surface, operating temperature should not exceed 85°C)

Compliant with Part L of the April 2006 Building Regulations



ENGLISH

Thermal Conductivity			
Mean Temp. °C	0	+20	+40
W/(m.K)	0.035	0.037	0.040

Standards

BS476 Part 7:1997 Class 1

BS476 Part 6:1989

BS4370 Part 2:1973

DIN 53495

DIN 4109

Specifications:

Material	Nitrile Rubber
Dimensions	2000 x 500mm
Thickness	9mm
Thermal Conductivity	0.034 W/mK, 0.036 W/mK, 0.038 W/mK, 0.04 W/mK
Colour	Black
Length	2000mm
Width	500mm