


FAG

UKP210

Plummer block housing unit

Plummer block housing units UKP, cast iron housing, with long base, radial insert ball bearing with adapter sleeve, RSR seals

Technical information

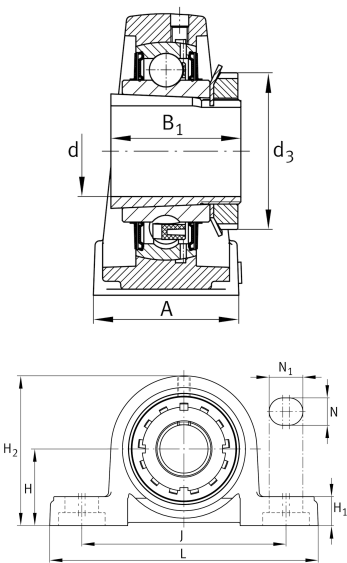

Your current product variant

Material	GG	Grey cast iron
Housing clearance	J7	Normal swivel torque

Main Dimensions & Performance Data

d	45 mm	Bore diameter
L	206 mm	Length total
H 2	114 mm	Height
≈m	2.95 kg	Weight

Mounting dimensions

J	159 mm	Distance fixing bore
N	20 mm	Width (slot)
N 1	25 mm	Length (slot)

Dimensions

H	57.2 mm	Distance shaft axis
A	60 mm	Width (base)
H 1	21 mm	Heigth (base)
B 1	55 mm	Locking collar total width
Q	M6	Connection thread for lubrication



Additional information

P210	Housing
UK210	Bearing designation

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.