

LADDER LOCKOUTS

Padlockable plates and barriers that prevent unauthorised use of damaged, defective or out-of-service ladders.

A defective ladder that gets used by mistake is a major fall risk. Ladder lockouts physically block the rungs at the base of the ladder, preventing anyone from climbing until the device is removed by an authorised inspector. Adjustable variants accommodate flat-rung and round-rung ladders of different sizes.



WHEN TO USE

- On every ladder taken out of service following a failed inspection.
- On ladders awaiting repair, recertification or disposal.
- On ladders restricted from use during specific work activities (e.g. around live electrical equipment).

HOW TO CHOOSE

- **Rung Type.**
 - Flat-rung adjustable lockouts for industrial ladders with flat steps.
 - Round-rung adjustable lockouts for traditional round-rung ladders.
- **Material.** Galvanised steel with powder-coat finish for outdoor and harsh environments.

PAIRS WITH: Lockout Padlocks · Lockout Tags · Signs & Labels

LADDER LOCKOUTS

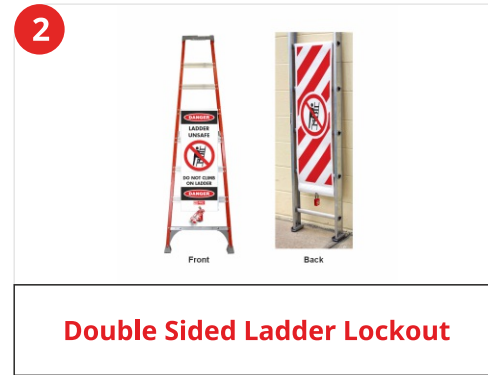


Image Ref.	RS Stock No.	Colour	Type	Material	Dimensions	Weight
1	694401	Yellow	Steel Ladder Lockout	Steel With Powder Coated Finish	1575 x 330 mm	9 Kgs
2	710502	White	Double Sided Ladder Lockout	PVC	1778 x 330 mm	230 Grams
3	802217	Red	Adjustable Steel Ladder Lockout	Steel With Powder Coated Finish	457 X 381 X 94 mm	4 Kgs
4	802218	Yellow	Adjustable Steel Ladder Lockout	Steel With Powder Coated Finish	457 X 381 X 46 mm	4 Kgs

HOW TO CHOOSE

- **Ladder Tag Holder** - Smaller ABS holder (213 × 58 mm) sized for ladder uprights; same insert and kit system as scaffolding tags.
- **Ladder Tag Inserts** - Yellow and green inserts for ladder inspection status.
- **Ladder Tag Kit** - Kit includes holder, inserts and marker pen.



Image Ref.	RS Stock No.	Colour	Product Type	Material	Dimensions	Weight
1	441223	White	Ladder Tag Holder	ABS	213 x 58 x 6 mm	300 Grams
2	441225	Yellow	Ladder Tag Insert	PVC	168 x 50 mm	60.6 Grams
3	204529	Yellow	Ladder Tag Kit	PVC, ABS, Fiber tip & Black Ink	Holder: 213 x 58 x 6 mm, Inserts: 168 x 50 mm	350 Grams