



SETRON, cylindrical fuse link, 22x58 mm, 40 A, aM, Un AC: 690 V

Figure similar


Model		
product brand name	SETRON	
product designation	Cylindrical fuse link	
General technical data		
operating class of the fuse link	aM	
type of voltage of the operating voltage	AC	
supply voltage at DC	250 V	
Dissipation		
power loss [W]	3.2 W	
power loss [W] for rated value of the current at AC in hot operating state per pole	3 W	
Main circuit		
operational current rated value	40 A	
Product details		
product component striker	No	
Mechanical Design		
mounting position	Any, preferably vertical	
net weight	53 g	
Approvals Certificates		
General Product Approval	other	Environment



[Confirmation](#)

[Environmental Confirmations](#)

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	
Industry Mall (Online ordering system)	
https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW8217-1	
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)	
https://support.industry.siemens.com/cs/ww/en/ps/3NW8217-1	
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)	
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW8217-1	
CAx-Online-Generator	
http://www.siemens.com/cax	
Tender specifications	
http://www.siemens.com/specifications	

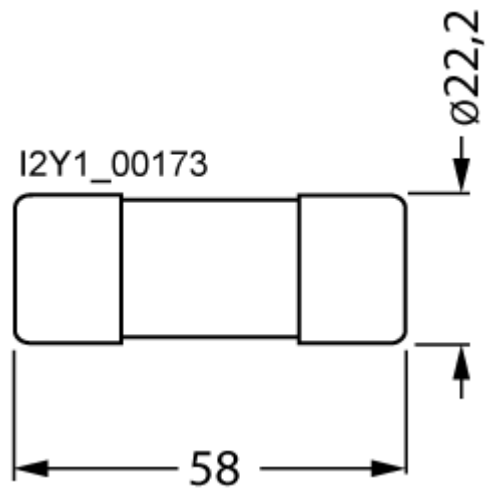

last modified:

4/11/2025 

