


# E40522



## Process adapters aseptic flange DIN11864-2A

ADAPT DIN11864-2A DN40

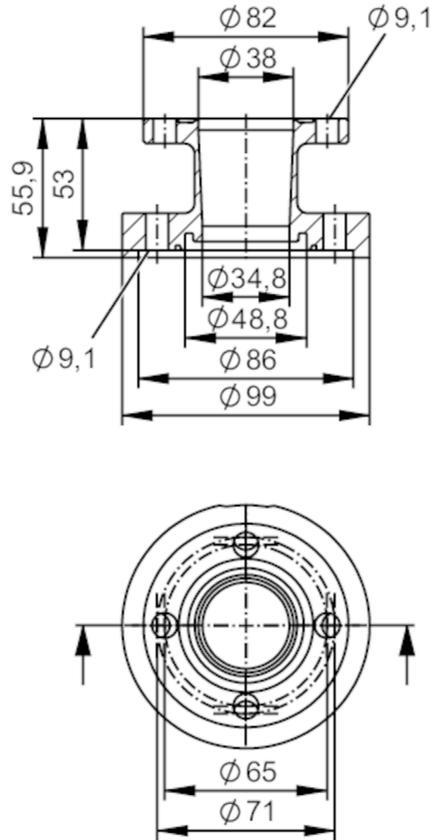

Application	
Design	for volumetric flow meters SMF
Application	food and beverage industry; hygienic systems
Pressure rating	40 bar 4 MPa
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight [g]	2939.3
Materials	stainless steel (316L/1.4404)
Nominal diameter	DN40 (1 1/2")
Sensor connection	ifm-specific device flange
Process connection	aseptic flange DIN 11864-2A
Process connection suitable for pipe standard	(DIN EN 10357 series A); (DIN 11866 series A); (DIN 11850 series 1); (DIN 11850 series 2)
Surface characteristics Ra/Rz of the wetted parts	Ra $\leq$ 0.4 $\mu$ m

# E40522



## Process adapters aseptic flange DIN11864-2A

ADAPT DIN11864-2A DN40

Accessories	
Items supplied	screws 8
Remarks	
Pack quantity	2 pcs.