


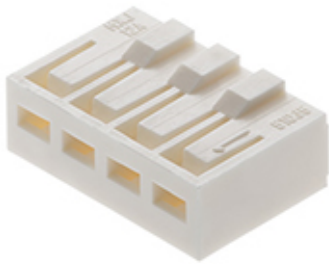

Part Number : [510351100](#)
Product Description : 2.50mm Pitch, Board-In Crimp Housing, Single Row, 11 Circuits, Natural
Series Number : 51035
Status : Active
Product Category : Connector Housings



Documents & Resources

Drawings
[510351100_sd.pdf](#)
[SPK-51035-001-001.pdf](#)
[SPK-51035-001-002.pdf](#)

3D Models and Design Files
[510351100_stp.zip](#)

Specifications
[PS-51035-001-001.pdf](#)
[PS-51035-002-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	51035
Description	2.50mm Pitch, Board-In Crimp Housing, Single Row, 11 Circuits, Natural
Application	Signal
Product Name	Board-in
UPC	800754298629

Physical

Circuits (maximum)	11
Color - Resin	Natural
Gender	N/A
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	475.200/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C

Use with Part(s)

Description	Part Number
-------------	-------------

2.50mm Pitch Board-in Male Crimp Terminals	<u>50097</u>
---	--------------

This document was generated on Apr 24, 2025