

FEATURES

- 15.5W Power consumption LED gear tray
- 5000K
- 1030 lumens
- Polycarbonate base
- Opal polycarbonate diffuser
- Steel gear tray
- White bezel
- 3-hour emergency maintained
- IP54 rated: protection against solid bodies larger than 1mm

LED Emergency Lighting Bulkhead 15.5 W

RS Stock No.: 795-9820



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This IP54 emergency Led bulkhead features polycarbonate base and diffuser and steel gear tray. This LED emergency bulkhead offers an energy saving and cost effective solution to fulfil emergency lighting requirements. Ideal applications of this emergency LED bulkhead are in corridors, foyers and general circulation areas.

General Specifications

Lamp Type	LED
Luminosity	1030lm
Colour Temperature	5000K
Maintained	Maintained
Material	Polycarbonate
Finish	White
Duration	3h
Lamp Supplied	Yes
Applications	LED emergency exit signs are ideal for commercial, industrial and retail applications and can be found in: Corridors, Workshops, Emergency exits

Electrical Specifications

Wattage	15.5W
Voltage Rating	230V

Mechanical Specifications

Width	325mm
Depth	100mm
Fitting Type	Bulkhead
Gear Tray	Steel gear tray


Protection Category

IP Rating	IP54
-----------	------

Approvals

Compliance/Certifications	RoHS
---------------------------	------



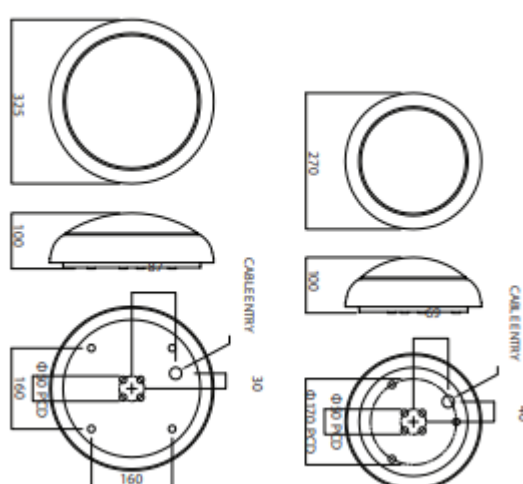

PRODUCT CODE	DESCRIPTION
795-9811	IP54 LED Bulkhead, White bezel, Opal diffuser - 5000K
795-9820	IP54 LED Bulkhead, emergency
795-9823	IP54 LED Bulkhead, micro-wave