

# HC-B 24-ADP-B 6-GY - Adapter plate



1660407

<https://www.phoenixcontact.com/gb/products/1660407>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



HEAVYCON adapter plate, type B24 on B6, for panel cutouts of type B24, gray

## Commercial data

Item number	1660407
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	AF7AZD
Product key	AF7AZD
Catalog page	Page 648 (C-4-2015)
GTIN	4017918022044
Weight per piece (including packing)	37.98 g
Weight per piece (excluding packing)	37.98 g
Customs tariff number	85389099
Country of origin	DE

# HC-B 24-ADP-B 6-GY - Adapter plate



1660407

<https://www.phoenixcontact.com/gb/products/1660407>

## Technical data


### Notes

General	For panel cutouts of type B24, cannot be used for panel mounting bases having a pre-mounted protective cover
General	Cannot be used with HC-STA and HC-EVO housings

### Product properties

Product type	Adapter plate
Type	B24

### Dimensions

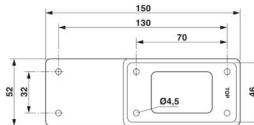Dimensional drawing	
Width	52 mm
Height	7 mm
Length	150 mm
Drill hole distance, horizontal	130 mm
Drill hole distance, vertical	27 mm
Hole diameter	4.5 mm

### Installation dimensions

Width of the assembly cutout	36 mm
Length of the assembly cutout	113 mm

### Material specifications

Color	gray
Material	PA
Flammability rating according to UL 94	HB
Seal material	PTS

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP54
Ambient temperature (operation)	-20 °C ... 100 °C

### Mounting

Assembly note	Cannot be used in panel mounting bases having a pre-mounted cover
---------------	---

HC-B 24-ADP-B 6-GY - Adapter plate




1660407

<https://www.phoenixcontact.com/gb/products/1660407>

## Drawings

## Dimensional drawing

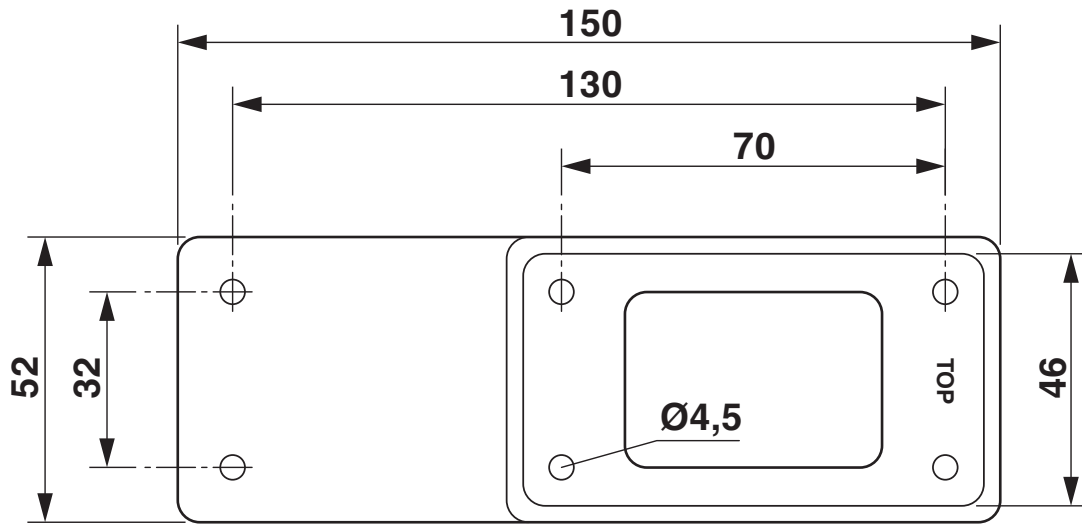

## Dimensional drawing

# HC-B 24-ADP-B 6-GY - Adapter plate

1660407

<https://www.phoenixcontact.com/gb/products/1660407>



## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/gb/products/1660407>



**EAC**

Approval ID: RU C-DE.AI30.B.01102

# HC-B 24-ADP-B 6-GY - Adapter plate



1660407

<https://www.phoenixcontact.com/gb/products/1660407>

## Classifications

### ECLASS

ECLASS-11.0	27440201
ECLASS-12.0	27440201
ECLASS-13.0	27440201

### ETIM

ETIM 9.0	EC002309
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

# HC-B 24-ADP-B 6-GY - Adapter plate



1660407

<https://www.phoenixcontact.com/gb/products/1660407>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd  
Halesfield 13, Telford  
Shropshire, TF7 4PG  
01952 681700  
[info@phoenixcontact.co.uk](mailto:info@phoenixcontact.co.uk)