


OPEN HOSE REELS FOR COMPRESSED AIR / STEEL

DLO series - Extra large - Rubber hose



Part number	Length (m)	Flow rate (l/min)	Max. operating pressure (bar)	Net weight (Kg)	Profile
DLO 1330ES	30.00	850.00	12.00	40,5	EUROPEAN
DLO 1920ES	20.00	2400.00	12.00	42	EUROPEAN

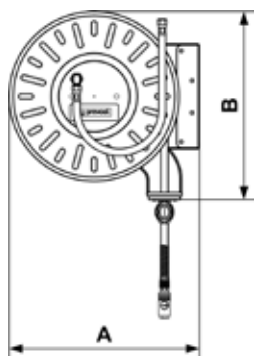

Part number	Dim. A (mm)	Dim. B (mm)	Ø int/ext (mm)
DLO 1330ES	615.00	610.00	13.00 / 20.00
DLO 1920ES	615.00	610.00	19.00 / 27.00