


Heavy Duty Pressure Transducers

PX3 Series


Product Nomenclature



For example, **PX3AN1BS150PAAAX** defines a PX3 Series Heavy Duty Pressure Transducer, Metri-Pack 150, standard (UL V-0) electrical connector type, 1/4-18 NPT pressure port type, brass pressure port material, silicone: -40 °C to 125 °C [-40 °F to 257 °F] seal material and temperature range, 150 psi pressure range, absolute pressure reference, ratiometric: 0.5 Vdc to 4.5 Vdc output transfer function, no special

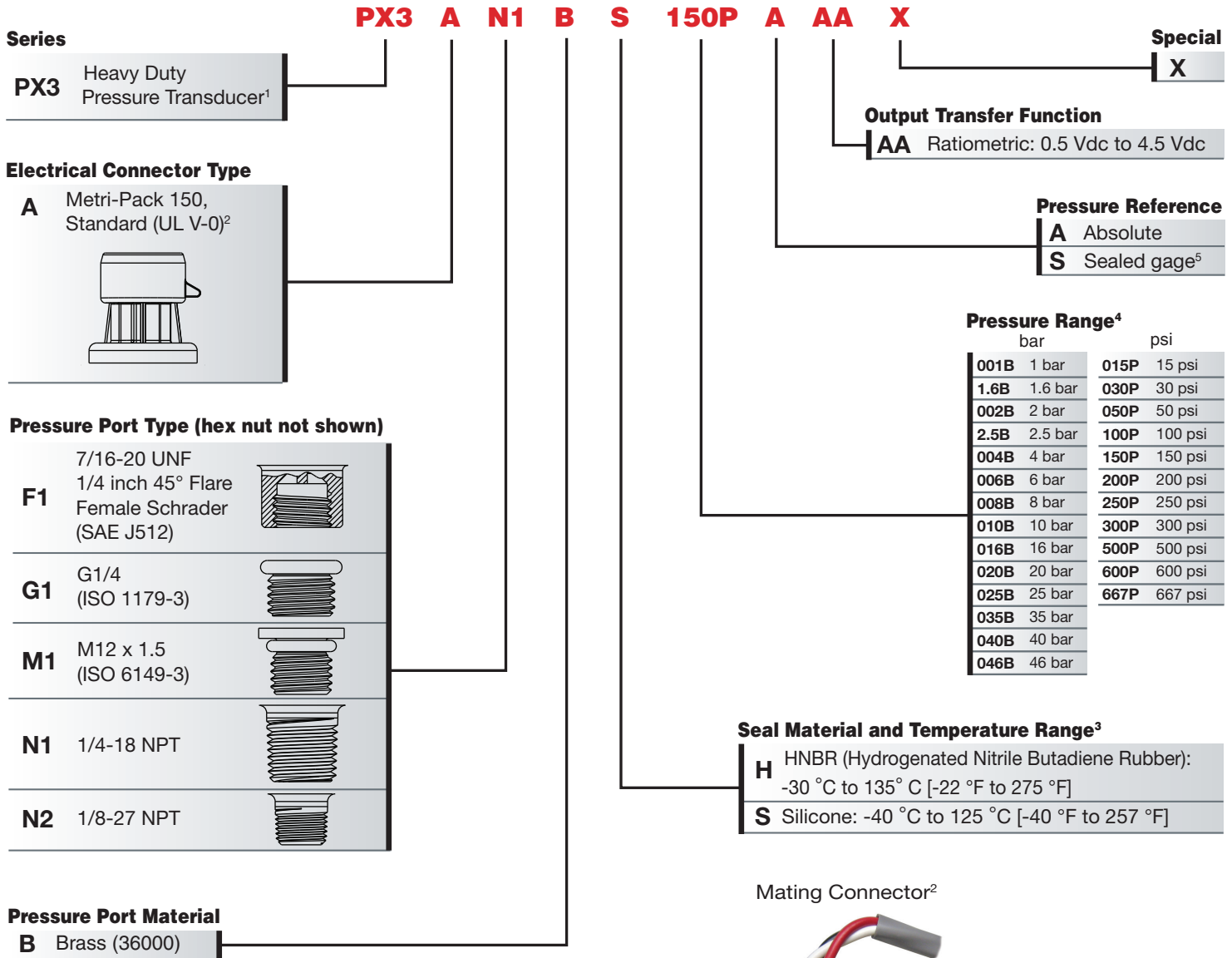

Mating Connector²

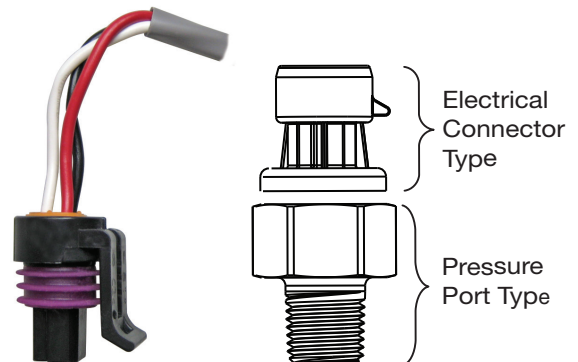

¹ Not all catalog listing combinations are available. Custom products are available. Please contact Honeywell.
² Metri-Pack 150 mating connectors with shielded cable and 22 AWG wire are available from Honeywell. Order part no. 3685301 for one meter cable length and part no. 3685302 for three meter cable length.
³ See Table 5 for seal material media compatibility.
⁴ Custom calibration pressure ranges are available.
⁵ Sealed gage option only available in pressure ranges at or above 8 bar | 100 psi.