

BD 43/35 C CLASSIC EP

Mains-operated and affordable: the scrubber dryer with disc technology cleans up to 1700 m²/h. For efficient basic and maintenance cleaning of areas up to 900 m².



Order no. 1.515-401.0

- Efficient single-disc engineering
- Mains operated
- Non-corrosive frame

Technical data

EAN code		4054278059532
Drive type		Mains operation
Traction drive		Advance by brush rotation
Working width of brushes	mm	430
Working width, vacuuming	mm	750
Tank of fresh/dirty water	l	35 / 35
Theoretical area performance	ft ² /hr	1720
Practical area performance	m ² /h	1250
Brush rotational speed	rpm	180
Brush contact pressure	g/cm ² / kg	30 - 40 / 26.5 - 28.5
Water consumption	l/min	max. 2.7
Sound pressure level	dB(A)	70
Current type	V / Hz	230 / 50
Rated input power	W	1400
Colour		anthracite
Weight without accessories	kg	48
Dimensions (L × W × H)	mm	1135 × 520 × 1025

Users must receive training on this device.

Equipment

Disc brush	Piece(s)	1
2-tank system		■
Mains operation		■
Squeegee, v-shape		■

■ Included in delivery.



Robust and durable control elements

- Designed for daily use.
- Robust, durable, reliable machine.



Simple operation thanks to EASY-Operation Panel


- Clear control panel with self-explanatory symbols
- Brief familiarisation stages
- Easy to use, colour coded control elements



Small, compact machine

- Extremely manoeuvrable machine
- Clear view of surfaces to be cleaned.

EQUIPMENT FOR BD 43/35 C CLASSIC EP 1.515-401.0

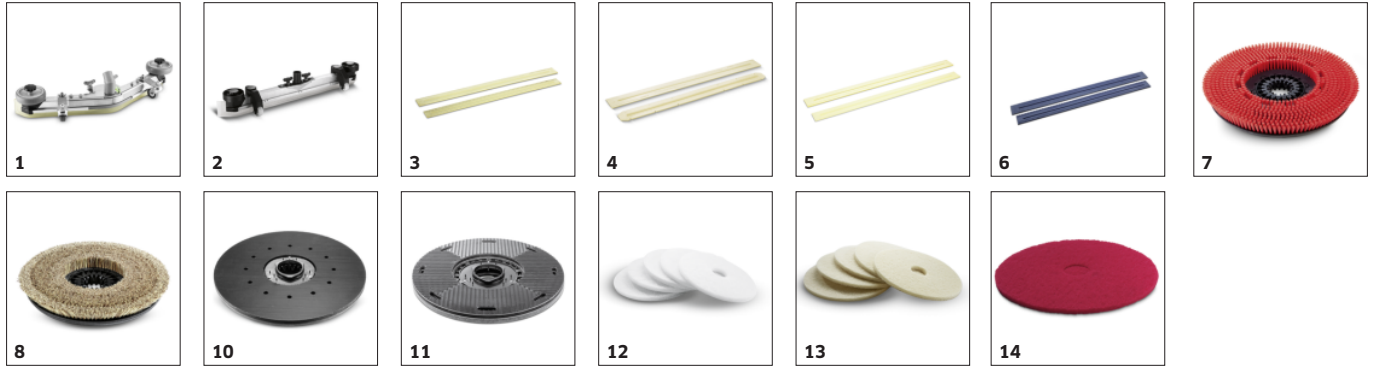

		Order no.	Description	
SUCTION BARS AND SQUEEGEES				
Suction bar, complete				
Suction bar v-shaped 750mm CN, 750 mm, V-shaped	1	4.777-115.0		■
Squeegee, 850 mm, straight	2	4.777-401.0	Straight suction bar, with support rollers. Squeegee blades are made from oil-resistant, transparent polyurethane and are easy to replace.	□
Squeegees for suction bars				
Rubber lip set oil resistant BR-BD530,55, oil-resistant, grooved, 890 mm	3	6.273-207.0	Squeegee blade kit includes front and rear squeegee blades, 870 mm. Grooved squeegee blades of hard-wearing, oil-resistant, transparent polyurethane. For all standard floors.	□
Suction lips, oil-resistant, slotted, 890 mm	4	6.273-229.0	Squeegee blade kit includes front and rear squeegee blades, 870 mm. Slotted squeegee blades of hard-wearing, oil-resistant, transparent polyurethane. For sensitive floors.	□
Suction lips, oil-resistant, closed, 890 mm	5	6.273-290.0	Suction lip set, consisting of front and rear suction lip. 890 mm long. In an enclosed design made from wear-resistant, oil-resistant and transparent polyurethane. For textured floors.	□
Rubber lip set standard, Natural rubber, 890 mm	6	6.273-213.0	Squeegee blade kit includes front and rear squeegee blades, 870 mm. Soft natural rubber grooved squeegee blades. For all standard floors.	□
DISC BRUSHES FOR BD				
Disc brush, medium, red, 430 mm	7	4.905-022.0	For general cleaning of all floors. Standard with D 43.	■
Disc brush, soft, natural, 430 mm	8	4.905-023.0	Made of natural fibres for cleaning and polishing. Fits D 43.	□
Disc brush, hard, black, 430 mm	9	4.905-025.0	For stubborn dirt and deep cleaning. Only for hard-wearing surfaces. Fits D 43.	□
DISC PADS / PAD DRIVE BOARDS				
Pad drive board				
Pad disk complete STRONG D43, 403 mm	10	4.762-592.0		□
Pad drive board, 403 mm	11	4.762-533.0	For cleaning with pads. With quick-change coupling and Centerlock. Fits D 43.	□
Pads				
Pad, very soft, white, 432 mm, 5 Piece(s)	12	6.369-469.0	5 polishing pads, very soft, white, without grit, 432 mm diameter. For polishing floors.	□
Pad, soft, beige, 432 mm, 5 Piece(s)	13	6.371-081.0	Soft, with slight grain, for polishing.	□
Pad, medium-soft, red, 432 mm, 5 Piece(s)	14	6.369-470.0	5 pads, medium-soft, red, 432 mm diameter. For cleaning all floors.	□

■ Included in delivery. □ Available accessories.

EQUIPMENT FOR BD 43/35 C CLASSIC EP



1.515-401.0



		Order no.	Description	
DISC PADS / PAD DRIVE BOARDS				
Pads				
Pad, medium-hard, green, 432 mm, 5 Piece(s)	15	6.369-472.0	5 pads, medium-hard, green, 432 mm diameter. For removing stubborn dirt and basic cleaning.	☐
Pad, hard, black, 432 mm, 5 Piece(s)	16	6.369-473.0	5 pads, hard, black, 432 mm diameter. For removing stubborn dirt and basic cleaning.	☐
Diamond pads				
Diamond pad, coarse, white, 432 mm, 5 Piece(s)	17	6.371-256.0	White diamond pad (coarse) with a diameter of 432 mm for coarse cleaning and restoration. Removes small scratches, for a clean, silky matt surface.	☐
Diamond pad, medium, yellow, 432 mm, 5 Piece(s)	18	6.371-257.0	Yellow diamond pad (medium) with a diameter of 432 mm for coarse cleaning and restoration. Removes fine scratches and ensures a more homogeneous and shinier surface.	☐
Diamond pad, fine, green, 432 mm, 5 Piece(s)	19	6.371-238.0	Green diamond pad (fine) with a diameter of 432 mm. For effortless polishing of laminated floors, terrazzo and natural stone surfaces.	☐
Melamine pads				
Melamine pad, 432 mm, 2 Piece(s)	20	6.371-023.0	Melamine pad set with 432 mm diameter for our single-disc machines with a working width of 43 cm and our scrubber driers with the D 43 brush head. For cleaning microporous surfaces.	☐
OTHER ACCESSORIES FOR SCRUBBER DRYERS				
RM Dosierstation				
Cleaning agent dosage kit, wall mounted DS 3	21	2.641-811.0	Directly connectable with the tab, water and detergent will be filled in the fresh water tank in the preset mixture. Can also be used with filling system kit.	☐
Miscellaneous				
Filling hose	22	6.680-124.0	1,500-mm filling hose for easy device filling from a water tap. With universal tapered fitting for all standard taps.	☐
Cleaning tool kit accessories				
Adapter Homebase	23	5.035-488.0	Fastener for various hooks and clips on the machine.	☐
Universal hook kit	24	4.070-075.0	Hook and adaptor kit for attachment to the Home Base rail scrubber drier by Kärcher. Ideal for space-saving storage of hoses (for example, spray suction attachment kit) on the machine.	☐
Double hook	25	6.980-077.0	Double hook for attaching rubbish bags, etc. to the machine. Only for use with the Homebase adapter 5.035-488.0.	☐
Holder handhold grey	26	6.980-078.0	Mop clip for attaching a mop to the machine. Only for use with the Homebase adapter 5.035-488.0.	☐
Bottle holder	27	6.980-080.0	Suitable for transporting spray bottles - only in conjunction with Home Base adapter 5.035-488.0.	☐
Home Base Box Kit	28	4.035-406.0	The Box kit provides enough space for three cleaning agent bottles along with cloths, scrapers, spare rubbish bags, gloves, etc.	☐

■ Included in delivery. □ Available accessories.

EQUIPMENT FOR BD 43/35 C CLASSIC EP 1.515-401.0

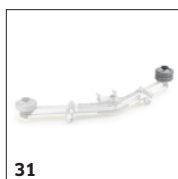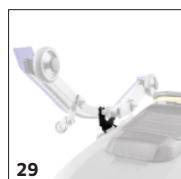

		Order no.	Description	
OTHER ACCESSORIES FOR SCRUBBER DRYERS				
Cleaning tool kit accessories				
Holder suction bar complete	29	9.753-088.0		☐
KITS				
Other attachment kits				
Add-on kit drain hose ball valve	30	2.643-977.0	The drain hose enables convenient metered draining of dirty water from the tanks in our BD 43/25 C and BD 43/35 C scrubber driers. Water flow regulation using a ball valve.	☐
Set deflector roll stack formation SB	31	4.035-619.0		☐
Suction hose accessories	32	4.444-015.0	For vacuuming water out of corners or containers (e.g. freezers).	☐
SPRAY EXTRACTION CLEANERS				
Other				
Cleaning agent container, complete	33	4.070-006.0	Kit consisting of cleaning agent container and Home Base adapter. For connecting Home Base rail.	☐
SPRAYERS				
Pump spray bottle 1 l	34	6.394-409.0	1 litre pump spray bottle – including pump and pressure tank – for easy, uniform spraying for cleaning or crystallising.	☐

■ Included in delivery. □ Available accessories.