

# A-INL-M25-P-GY - Counter nut

1411208

<https://www.phoenixcontact.com/gb/products/1411208>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Counter nut, for threads M25 x 1.5, color: silver-gray RAL 7001



## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 1411208             |
| Packing unit                         | 5 pc                |
| Minimum order quantity               | 5 pc                |
| Sales key                            | AF7DZX              |
| Product key                          | AF7DZX              |
| Catalog page                         | Page 686 (C-2-2019) |
| GTIN                                 | 4046356923408       |
| Weight per piece (including packing) | 3.94 g              |
| Weight per piece (excluding packing) | 3.75 g              |
| Customs tariff number                | 39269097            |
| Country of origin                    | TR                  |

# A-INL-M25-P-GY - Counter nut

1411208

<https://www.phoenixcontact.com/gb/products/1411208>




## Technical data

### Product properties

|              |          |
|--------------|----------|
| Product type | Flat nut |
| Thread type  | M25      |

### Dimensions
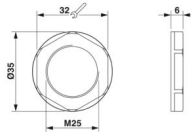
|                             |                                                                                    |
|-----------------------------|------------------------------------------------------------------------------------|
| Dimensional drawing         |  |
| Length                      | 6 mm                                                                               |
| Diameter                    | 25 mm                                                                              |
| Connecting thread diameter  | 25 mm                                                                              |
| Wrench size, counter nut    | 32 mm                                                                              |
| Hexagon angular dimension   | 35 mm                                                                              |
| Thread type connection side | M25 x 1.5                                                                          |
| Thread pitch                | 1.5 mm                                                                             |

### Material specifications

|                                        |                        |
|----------------------------------------|------------------------|
| Color                                  | silver grey (RAL 7001) |
| Material                               | PA                     |
| Flammability rating according to UL 94 | V2                     |

### Cable/line

|              |     |
|--------------|-----|
| Halogen-free | yes |
|--------------|-----|

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 100 °C |
|---------------------------------|-------------------|

# A-INL-M25-P-GY - Counter nut


1411208

<https://www.phoenixcontact.com/gb/products/1411208>



## Drawings

Dimensional drawing

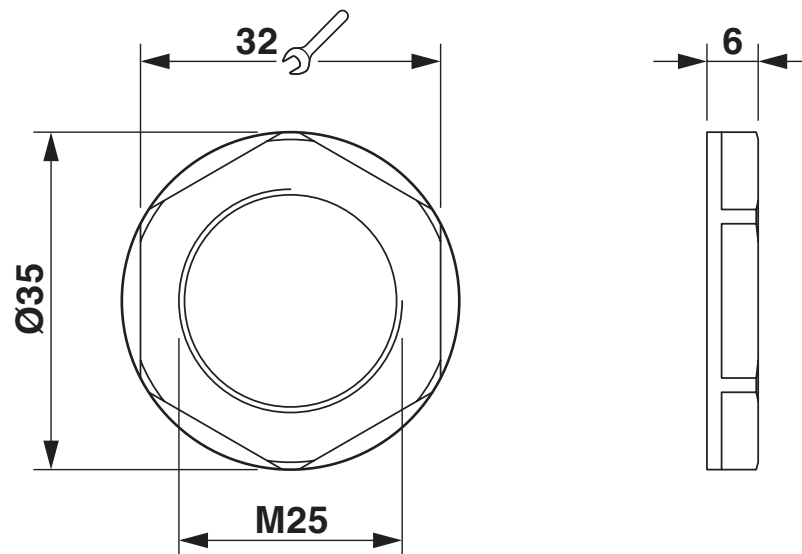

Dimensional drawing

# A-INL-M25-P-GY - Counter nut



1411208

<https://www.phoenixcontact.com/gb/products/1411208>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27140807 |
|-------------|----------|

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000879 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31161700 |
|-------------|----------|

# A-INL-M25-P-GY - Counter nut



1411208

<https://www.phoenixcontact.com/gb/products/1411208>

## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd  
Halesfield 13, Telford  
Shropshire, TF7 4PG  
01952 681700  
[info@phoenixcontact.co.uk](mailto:info@phoenixcontact.co.uk)