




LED FIL T20X115 E14 DIM 2.5W (25W) 250lm 927 Clear

Article number: 147033

BAI LED Filament Tube T20x115mm E14 220-240V 2.5W (25W) 250lm 2700K CRI90-100 Dimmable Clear FLOS LED-lamp

LED Filament Tube Bulb – The Modern, Sustainable Alternative to the Classic Incandescent. This E14 LED filament tube bulb is the ideal energy-efficient replacement for the once-popular 25W incandescent bulb. Featuring filament technology, it delivers the same warm glow while using significantly less energy and lasting much longer. With a high color rendering index (CRI90), it ensures true-to-life color accuracy – making it perfect for highlighting paintings or artwork. The bulb is dimmable (depending on the type of dimmer and number of bulbs connected), combining classic aesthetics with modern efficiency and visual fidelity.

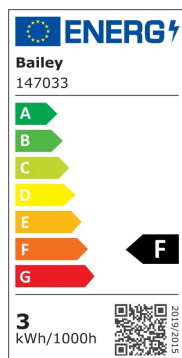

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL T20X115 E14 DIM 2.5W (25W) 250lm 927 Clear
Brand	Bailey
Productseries	LED Filament tube
Producttype	T20X115 E14 927 CL

ETIM specifications

Socket	E14
Luminous flux [lm]	250 - 250
Nominal voltage [V]	230 - 230
Lamp power [W]	2.5 - 2.5
Colour temperature [K]	2700 - 2700
Diameter [mm]	20
Length [mm]	110
Dimmable	Yes
Lamp shape	Tube, single-ended
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Clear
Lamp designation	Other
Colour rendering index CRI	90-100
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	250
Power factor	0.9
Lamp efficacy [lm/W]	100
Nominal current [mA]	11 - 11
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	3
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Glass

Alternative articles



143312

LED FIL T20X115 E14 DIM 4W
(35W) 400lm 827 Clear

Complementary articles



142227

Lampholder Porcelain E14 White



142228

Lampholder Porcelain E14 Black