


EXTENSION CABLE M12 WITH 4-WIRE TPE INSULATED CABLE

Extension cables with 4-pin M12 female connector suitable for TRM and TRC probes

- OVERMOULDED connection
- 4-wire TPE insulated cable
- IP67 protection degree
- straight or elbow type connector versions

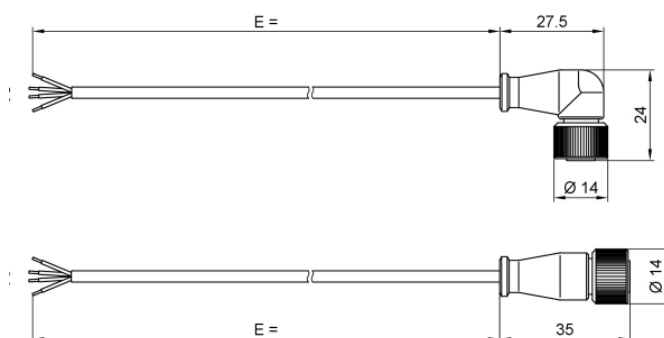

Product type	accessory
Accessory type	extension cable
Type of connector	female 4-pin connector with M12x1 metal screw lock (in accordance with DIN -VDE0627 STANDARDS)
Connection body material	TPE (MOULDED)
Maximum connector temperature	90°C
Ambient tightness degree (*) (*) in accordance with IEC 60529	IP67
Female connector	overmoulded straight M12 female connector overmoulded right-angle M12 female connector
Male connector	contatti aggraffati con portacontatti
Extension cable	TPE a 4 wire
Cable conductors	copper tinned
Number of cable conductors	4
Conductor dimension	AWG 24
Conductor feature	strand (7 wire)
Primary insulation	PP (polypropylene)
Outside diameter of single conductor (*)	about Ø 1.05 mm
Primary insulation colour	2 white, 2 red
Secondary insulation	TPE (thermoplastic rubber)
Secondary insulation colour	black
Cable size or external shape	about Ø 4 mm
Working temperature	-40 ÷ 105°C (6h @150°C)
Cable extension E=	1500 mm 3 m 5 m
Dimensional notes	Extensions other than those listed can be produced for minimum quantities to be agreed (after our feasibility study)
Terminal electrical connection	stripped wires
Shield	
Variant	null