


Connecting cable NEBV-HPG2-PN-0.3-N-LE2

Part number: 8122832

FESTO

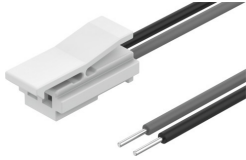

 [General operating condition](#)

Data sheet

Feature	Value
Max. number of valve coils	1
Cable designation	Without inscription label holder
Mounting position	optional
Product weight	2 g
Electrical connection 1, function	Field device side Switching output
Electrical connection 1, design	Angular
Electrical connection 1, connection type	Cable with socket
Electrical connection 1, cable outlet	Straight
Electrical connection 1, connector system	Connection pattern HP
Electrical connection 1, number of connections/cores	2
Electrical connection 1, used connections/cores	2
Electrical connection 1, type of mounting	Push-pull with interlock against unintentional pulling
Electrical connection 2, function	Power supply Controller side
Electrical connection 2, connection type	2x single wires
Electrical connection 2, connector system	Open end
Electrical connection 2, number of connections/cores	2
Electrical connection 2, used connections/cores	2
Operational voltage range DC	0 V ... 24 V
Shielding	no
Note on operation	Only operate with external power reduction
Cable length	0.3 m
Cable characteristic	For static applications
Bending radius, fixed cable	≥11 mm
Cable diameter	0.96 mm
Degree of protection	IP40
Ambient temperature	0 °C ... 50 °C
Storage temperature	-20 °C ... 70 °C
LABS (PWIS) conformity	VDMA24364 zone III
Note on materials	RoHS-compliant
Corrosion resistance class CRC	0 - No corrosion stress
Material housing	PEEK
Housing colour	grey
Material insulating sheath	PVC