


chiavi poligonali curve con attacco per leva di manovra cromate

- Da utilizzare in accoppiamento con le prolunghe tubolari 92

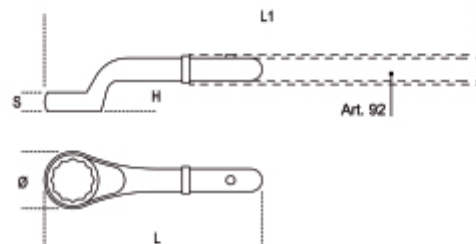

	art.	mm	Ø mm	H mm	L mm	L1 mm	S mm	kg
000910024	91 24	24	38	29,5	180	555	17,0	0,38
000910027	91 27	27	41	31,5	190	560	17,0	0,42
000910030	91 30	30	48	33,5	200	565	18,0	0,49
000910032	91 32	32	49	34,0	235	730	18,0	0,72
000910036	91 36	36	54	35,5	245	735	20,0	0,80
000910041	91 41	41	62	39,5	265	750	22,0	0,95
000910046	91 46	46	69	40,0	280	910	23,0	1,20
000910050	91 50	50	76	42,5	290	920	25,5	1,40
000910055	91 55	55	81	45,5	300	925	28,0	1,40
000910060	91 60	60	90	49,0	345	1050	30,5	2,30
000910065	91 65	65	98	53,0	355	1060	33,0	2,55
000910070	91 70	70	105	55,0	365	1065	35,5	2,78
000910075	91 75	75	110	57,5	375	1070	38,0	2,87
000910080	91 80	80	125	59,0	385	1075	40,5	3,90
000910085	91 85	85	125	59,0	385	1075	40,5	3,60
000910090	91 90	90	140	63,0	410	1100	45,0	5,10
000910095	91 95	95	140	63,0	410	1100	45,0	4,82
000910100	91 100	100	143	63,0	412	1100	45,0	4,80
000910105	91 105	105	146	63,0	415	1105	45,0	4,70