


# Flat gasket - HC-B10-SG-CBK - 1411484

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Replacement flat gasket, for HEAVYCON panel mounting base, HC-STA...AL, type B10, conductive



## Key Commercial Data

|                                      |   |
|--------------------------------------|---|
| Packing unit                         | 10 pc   |
| Minimum order quantity               | 10 pc   |
| GTIN                                 | <br>4 046356 932844 |
| GTIN                                 | 4046356932844   |
| Weight per Piece (excluding packing) | 5.050 g   |
| Custom tariff number                 | 40169300  |
| Country of origin                    | China   |

## Technical data

### Dimensions

|        |         |
|--------|---------|
| Length | 93.5 mm |
| Width  | 53 mm   |
| Height | 2 mm    |

### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 125 °C |
|---------------------------------|-------------------|

### General

|          |                 |
|----------|-----------------|
| Material | NBR, conductive |
| Color    | black           |


### Environmental Product Compliance

|            |   |
|------------|---|
| China RoHS | Environmentally Friendly Use Period = 50 years  |
|            | For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration" |

# Flat gasket - HC-B10-SG-CBK - 1411484

## Drawings

Dimensional drawing

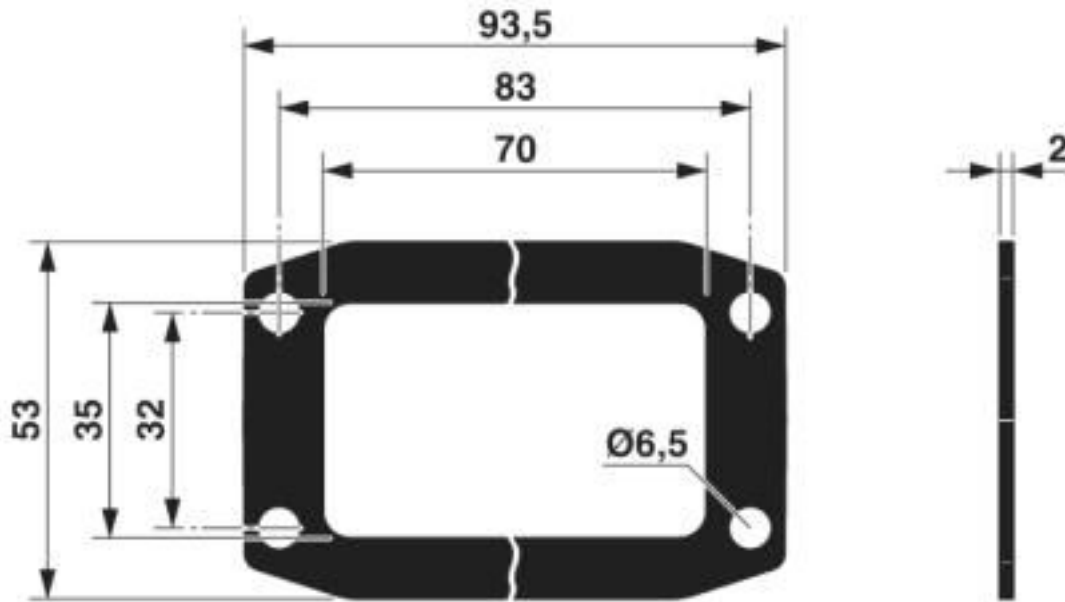

Dimensional drawing

## Classifications

### eCl@ss

|               |          |
|---------------|----------|
| eCl@ss 10.0.1 | 23071590 |
| eCl@ss 4.0    | 27140800 |
| eCl@ss 4.1    | 27140800 |
| eCl@ss 5.0    | 27143400 |
| eCl@ss 5.1    | 27143400 |
| eCl@ss 6.0    | 23071500 |
| eCl@ss 7.0    | 23071590 |
| eCl@ss 8.0    | 23071590 |
| eCl@ss 9.0    | 23071590 |

### ETIM

|          |          |
|----------|----------|
| ETIM 4.0 | EC002498 |
| ETIM 5.0 | EC002498 |
| ETIM 6.0 | EC000761 |
| ETIM 7.0 | EC000761 |

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 13.2 | 39131505 |
| UNSPSC 18.0 | 31401601 |

# Flat gasket - HC-B10-SG-CBK - 1411484

## Classifications

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 19.0 | 31401601 |
| UNSPSC 20.0 | 31401601 |
| UNSPSC 21.0 | 31401601 |

## Approvals

### Approvals

---

#### Approvals


EAC

---

#### Ex Approvals

---

## Approval details

|     |   |                          |
|-----|---|--------------------------|
| EAC |  | RU C-<br>DE.AI30.B.01102 |
|-----|---|--------------------------|

---