


MPC

直通外螺纹接头

Metal male straight

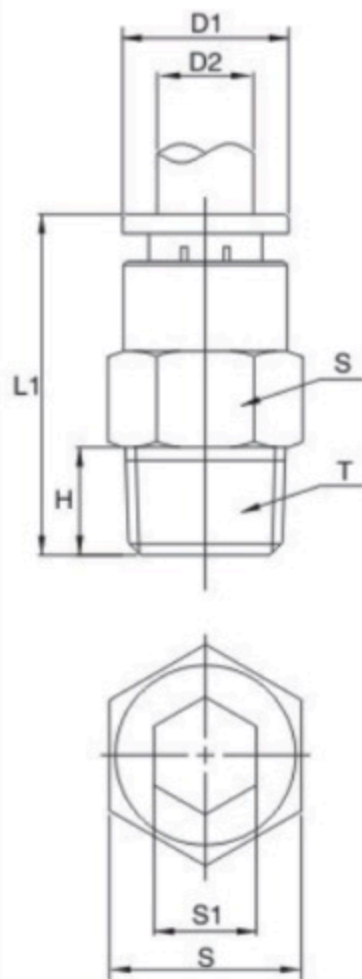

型号MODEL	L1	S1	H	S	T	D1	D2
MPC4-M5	19	2	3.6	8	M5		
MPC4-01	16	2.5	7	10	R1/8	Φ8	Φ4
MPC4-02	18	2.5	9	14	R1/4		
MPC4-03	19	2.5	9.5	17	R3/8		
MPC6-M5	25	2	4	12	M5		
MPC6-01	24	5	7	12	R1/8	Φ12	Φ6
MPC6-02	19	5	9	14	R1/4		
MPC6-03	19	5	9.5	17	R3/8		
MPC6-04	20	5	11	21	R1/2		
MPC8-M5	27	2	4	14	M5		
MPC8-01	27.5	5	7	14	R1/8	Φ14	Φ8
MPC8-02	27.5	6	9	14	R1/4		
MPC8-03	21	6	9.5	17	R3/8		
MPC8-04	21	6	11	21	R1/2		
MPC10-01	29.5	5	7	17	R1/8	Φ16	Φ10
MPC10-02	29	6	9	17	R1/4		
MPC10-03	24	8	9.5	17	R3/8		
MPC10-04	23	8	11	21	R1/2		
MPC12-01	30	5	7	19	R1/8	Φ18	Φ12
MPC12-02	32	6	9	19	R1/4		
MPC12-03	30	10	9.5	19	R3/8		
MPC12-04	23	10	11	21	R1/2		
MPC14-02	36	6	4	21	R1/4	Φ21	Φ14
MPC14-03	36	8	9.5	21	R3/8		
MPC14-04	35	10	11	21	R1/2		
MPC14-06	37	12	13	27	R3/4		
MPC16-02	36	6	9	24	R1/4	Φ23	Φ16
MPC16-03	37	10	9.5	24	R3/8		
MPC16-04	37	12	11	24	R1/2		
MPC16-06	37	12	13	27	R3/4		