

ALPHA

3470IDG100P62

EAN ...

Swivel castor, housing made of pressed steel, bright zinc plated, blue passivated, double ball bearing swivel head, wheel axle with nut, dustguard, plate fitting. Wheel centre made of Aluminium, Tread: heat resisting silicone rubber, damping, self-lubricating bushing




BETTER MOBILITY. BETTER LIFE.

Technical Data

Wheel diameter	100 mm
Wheel width	30 mm
Size of Plate	105 x 80 mm
Plate hole centres	80/77 x 60 mm
Plate hole	9 mm
Offset	40 mm
Swivel Interference	180 mm
Overall height	128 mm
Temperature	- 30 / + 250 °C
Standard	EN_12532
Weight	0.821 kg
Swivel Radius	90 mm
Hardness of tread	Shore A 75
Load capacity	80 kg
Load capacity (static)	160 kg

Dimensions

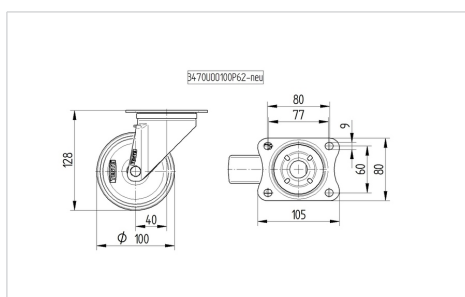

Advantages at a glance

Roll performance	● ● ● ○ ○
Movement noise	● ● ● ○ ○
Attrition	● ● ● ○ ○
Corrosion resistance	● ● ● ● ●