


Self-aligning ball bearings, cylindrical and tapered bore, cylindrical bore, unsealed

Principal dimensions			Basic load ratings		Fatigue	Speed ratings		Mass	Designation
d	D	B	dynamic	static	load limit P_u	Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
12	32	10	6,24	1,43	0,072	50000	32000	0,040	1201 ETN9

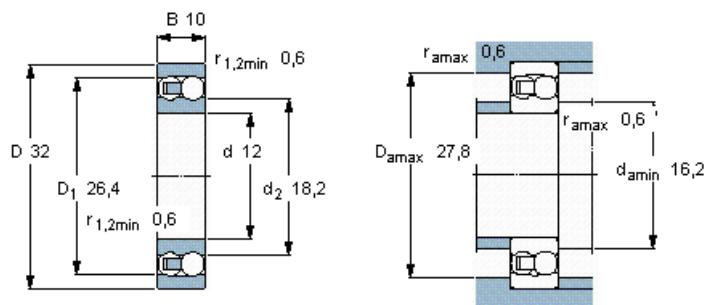

Calculation factors

e 0,33
 Y_1 1,9
 Y_2 3
 Y_0 2