




LED G9 Glass 3.7W (36W) 420lm 827 Clear

Article number: 142760

BAI LED Compact G9 Glass 230V-240V 3.7W 420lm (36W) 2700K Clear 300° 17x64mm Capsule LED-lamp

The LED compact series consists of lamps that are ideal as replacements for the 230V halogen lamps with G9 base due to their compact design. LED technology in a traditional halogen capsule for the same look & feel. Ambient temperature range: -20°C to +40°C.

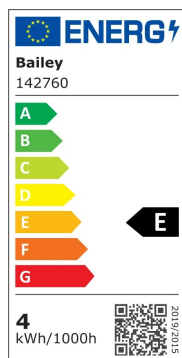

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED G9 Glass 3.7W (36W) 420lm 827 Clear
Brand	Bailey
Productseries	LED Capsule MV
Producttype	G9 827 CL

ETIM specifications

Socket	G9
Luminous flux [lm]	420 - 420
Nominal voltage [V]	220 - 240
Lamp power [W]	3.7 - 3.7
Colour temperature [K]	2700 - 2700
Diameter [mm]	17
Length [mm]	64
Dimmable	No
Lamp shape	Capsule/stick
Beam angle [°]	300 - 300
Colour	White
Type of glass/cover	Clear
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	420
Power factor	0.5
Lamp efficacy [lm/W]	114
Nominal current [mA]	40 - 40
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	10000
Weighted energy consumption in 1000 hours [kWh]	4
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG1
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	E
With twilight switch	No
Material of light bulb	Glass

Alternative articles



145774


LED G9 Glass DIM 4.2W (40W)
470lm 827 Clear



145242


LED FIL G9 DIM 3.5W (32W)
350lm 927 Clear

Complementary articles

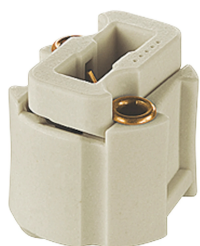

140268

BJB 25.830.1000.00 G9
Lampholder Ceramic

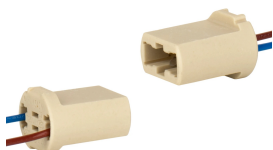

141211

Lampholder G9 6A 250V T250°C
250mm