


## Datasheet

### RPSMA-UFL RF coax cable assembly

RS Stock number 794-2904



### Dimensions: (mm)

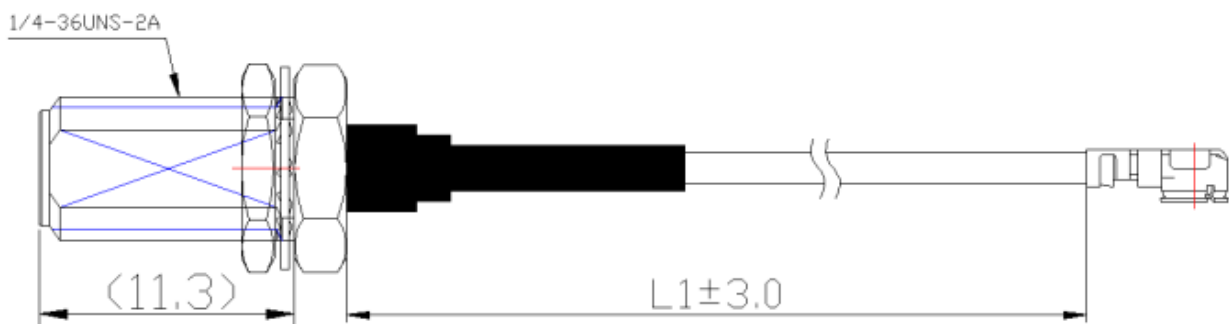

## Specification

### PRODUCT MATERIAL

1. RP-SMA B/H JACK CRIMP TYPE FOR  $\phi 1.37\text{mm}$  CABLE NUT x 1, WASHER x 1
2. U.FL-LP-088 Halogen Free For  $\phi 1.37\text{mm}$  Cable
3. U.FL-088 CONTACT For  $\phi 1.37\text{mm}$  Cable
4. 1.37mm CABLE TIN PLATED COLOR:BLACK
5. HEAT SHRINK TUBE F32  $\phi 2.5\text{mm}$  L=15.0mm COLOR:BLACK.

### ELECTRICAL PERFORMANCE:

1. IMPEDANCE: 50 OHMS
2. FREQUENCY RANGE: DC~3GHz
3. WORKING VOLTAGE: 250Vrms MAXIMUM
4. DIELECTRIC WITHSTANDING VOLTAGE: 750Vrms min.