
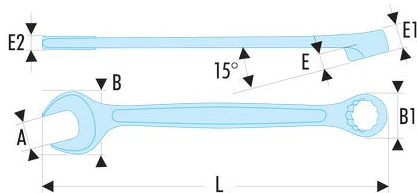


440.1P1/16SLS 440.SLS - Inch combination wrenches

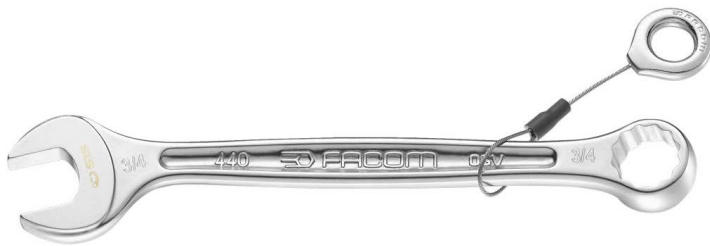

Description :

- Tool equipped with a FACOM SLS attachment solution, preventing any risk of accidental falls.
- The crimped "sliding" cable solution, selected and tested by FACOM, maintains user ergonomics (8 - 30 mm wrenches).
- Standard wrench for all current applications.
- High mechanical strength combined with compact size meeting aeronautical standards.
- Ring head:
 - Ring open end (size E) designed for better access to series or embedded screws.
 - OGV® profile with 12-point ring for powerful tightening while protecting the nut.
 - Ring head angled at 15°.
- Open end head:
 - Open end angled at 15°.
 - Open end head-handle geometry optimised for increased access.
- Dimensions in inches: from 1/4" to 1"5/16.
- Presentation: satin chrome finish.

A ["]:	1'1/16
--------	--------

B [mm]:	58,0
---------	------

B1 [mm]:	39,2
----------	------

C1 [mm]:	15,6
----------	------

E [mm]:	8,9
---------	-----

E1 [mm]:	15,6
----------	------

E2 [mm]:	10,4
----------	------

L [mm]:	295
---------	-----

[g]:	400
------	-----