

SEK CAB FLAT STD HF AWG28/7 20P 30,48m

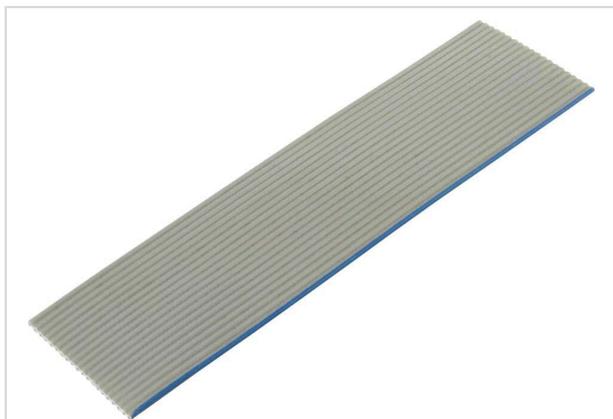


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 020 7001 900
Specification	SEK CAB FLAT STD HF AWG28/7 20P 30,48m
HARTING eCatalogue	https://harting.com/09180207001900

Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (flat)

Version

Cable length	30.48 m
Number of cores	20
Core structure	AWG 28/7

Technical characteristics

Impedance	110 Ω
Limiting temperature	-40 ... +105 °C unmoved -20 ... +105 °C moved

Material properties

Material (cable)	Non-halogenated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



Pushing Performance
Since 1945

Material properties

California Proposition 65 substances	Not contained
--------------------------------------	---------------

Specifications and approvals

Specifications	UL 1581
	UL 758

Approvals	CE
-----------	----

Commercial data

Packaging size	1
----------------	---

Net weight	1,279 g
------------	---------

Net weight	37 g/m
------------	--------

Country of origin	USA
-------------------	-----

European customs tariff number	85444993
--------------------------------	----------

GTIN	5713140024670
------	---------------

eCl@ss	27061801 Data and communication cable (copper)
--------	--

ETIM	EC003249
------	----------

UNSPSC 24.0	26121609
-------------	----------