


## Datasheet

# RS Replacement Hydraulic Filter Element, 20 $\mu$ m

RS Stock number 512-538



Dimensions: (mm)

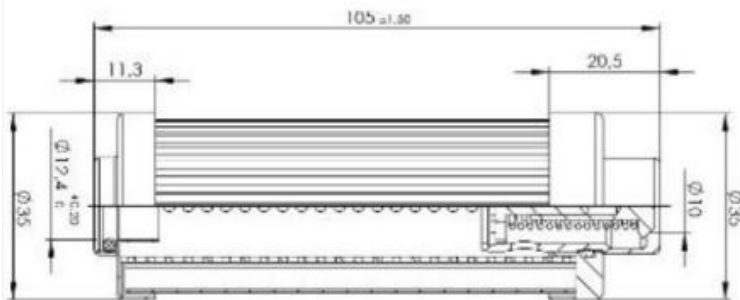

## Specification

- Nominal Flow: 30 l/m
- Nominal Flow: -10°C + 100°C
- Micron Rating: 20  $\mu$ m
- Filter Area: 332cm<sup>2</sup>
- Collapse pressure: 25 bar
- Bypass pressure: 3 bar
- Filter material: Inorganic glass fibre
- Metal Parts: Steel tin plated
- Plastic parts: Polyamide
- Valve Spring: Steel phosphate