


2005 CT4-U-20

1/4"-3/8"-1/2" Socket set

in 4/4 Check-Tool-Module

Code 2016257 ETIM EC002209
 EAN 4010886878408 UNSPSC 27-11-32-01
 Country of origin Germany eCl@ss 21-04-90-90
 Customs tariff number 82060000

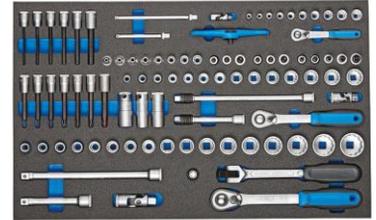

Article description

• Dimensions: 633 x 390 x 35 mm

Article parts list

1/4" Socket No. 20, 5.5 6 7 8 9 10 11 12 13 14 mm, 1/4" Reversible ratchet No. 2093 U-20, 1/4" Cross-handle ratchet No. 2093 U-3 T, 1/4" Extension No. 2090-4 -6, 97 148 mm, 1/4" Universal joint No. 2095, 3/8" Socket No. D 30, 8 9 10 11 12 13 14 15 16 17 18 19 21 22 mm, 3/8" Screwdriver bit socket No. IN 30 L, 4 5 6 7 8 10, 3/8" Screwdriver bit socket No. ITX 30 L, T20 T25 T27 T30 T40 T45 T50, 3/8" Socket No. TX 30, E5 E6 E7 E8 E10 E11 E12 E14, 3/8" Screwdriver bit socket No. IKS 30, 1 2 3, 3/8" Screwdriver bit socket No. IKS 30 PZD 1 2 3, 3/8" Screwdriver bit insert No. IS 30, 5.5 6.5 8 10 12 mm, 3/8" Spark plug insert with retaining spring 20.8 mm, 3/8" Spark plug insert with retaining spring 16 mm, 3/8" Spark plug insert with retention spring 18 mm, 3/8" Reversible ratchet No. 3093 U-20, 3/8" Extension with release No. 3090 A-5 -10, 3/8" Universal joint No. 3095, 1/2" Socket No. D 19, 10 11 12 13 14 15 16 17 18 19 21 22 23 24 27 30 32 mm, 1/2" Reversible ratchet 1/2" No. 1993 U-20, 1/2" Extension 1/2" No. 1990-5 -10, 125 250 mm, 1/2" Reducer 1/2" to 3/8" No. 1930, 1/2" Universal joint 1/2" No. 1995, 1/2" Swivel handle No. 1996, 255 mm

Article information

Contents (Qty of pieces)	91	Total height [mm]	35 mm
Net weight [kg]	7,64 kg	Material	Foam
Total length [mm]	633 mm	Storage	4/4 Check-Tool-Module
Total width [mm]	390 mm		