


3-PHASE INFEED TERMINAL FOR 3-PHASE BUSBARS,  
FOR SELF-PROTECTED COMBINATION MOTOR  
CONTROLLER (TYPE E),  
FOR CIRCUIT-BREAKERS 3RV SIZE S00/S0,

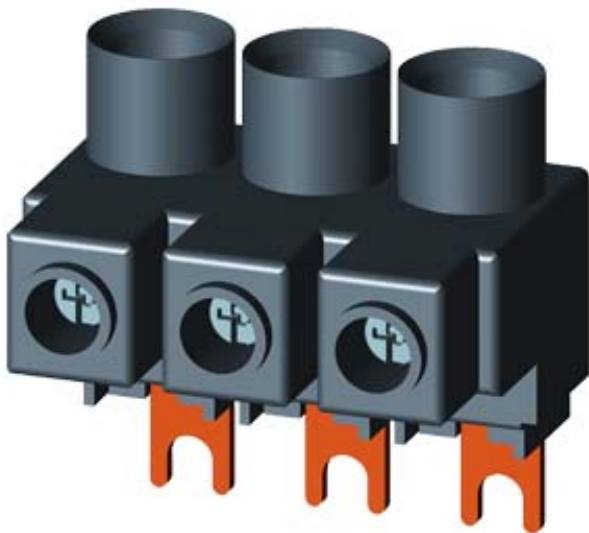



General technical data:		
product brand name		SIRIUS
product designation		3-phase infeed terminals of type E, size S0/S00, from above
Size of the circuit-breaker		S00, S0
Protection class IP / on the front		IP20
Insulation voltage / with degree of pollution 3		
• rated value	V	690
Ambient temperature		
• during storage	°C	-50 ... +80
• during operating	°C	-20 ... +60
Installation/mounting/dimensions:		
Width	mm	44
Height	mm	44.5
Depth	mm	32
Acceptability for application / makes the assembly of self-protected combination motor controllers (type E) according to UL 508 possible		Yes
Connections:		
Design of the electrical connection		

<ul style="list-style-type: none"> <li>• for main current circuit</li> </ul>		screw-type terminals
<b>Type of the connectable conductor cross-section</b> <ul style="list-style-type: none"> <li>• for main contacts <ul style="list-style-type: none"> <li>• solid</li> <li>• stranded</li> <li>• finely stranded <ul style="list-style-type: none"> <li>• with conductor end processing</li> </ul> </li> </ul> </li> <li>• for AWG conductors / for main contacts</li> </ul>		1x (2.5 ... 16 mm <sup>2</sup> ) 1x (2,5 ... 16 mm <sup>2</sup> )  1x (2.5 ... 16 mm <sup>2</sup> ) 1x (12 ... 6)

**Certificates/approvals:**

<b>Verification of suitability</b>	CE / UL / CSA / CCC
------------------------------------	---------------------

<b>General Product Approval</b>	<b>Test Certificates</b>
 	<a href="#">Manufacturer</a>

<b>Shipping Approval</b>
     

<b>Shipping Approval</b>	<b>other</b>
	<a href="#">Manufacturer</a> <a href="#">other</a> 

**Further information:**

- Information- and Downloadcenter (Catalogs, Brochures,...)**  
<http://www.siemens.com/industrial-controls/catalogs>

---

- Industry Mall (Online ordering system)**  
<http://www.siemens.com/industrial-controls/mall>

---



- CAX-Online-Generator**  
<http://www.siemens.com/cax>

---

- Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**  
<http://support.automation.siemens.com/WW/view/en/3RV2925-5EB/all>

---

- Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**  
[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3RV2925-5EB](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3RV2925-5EB)

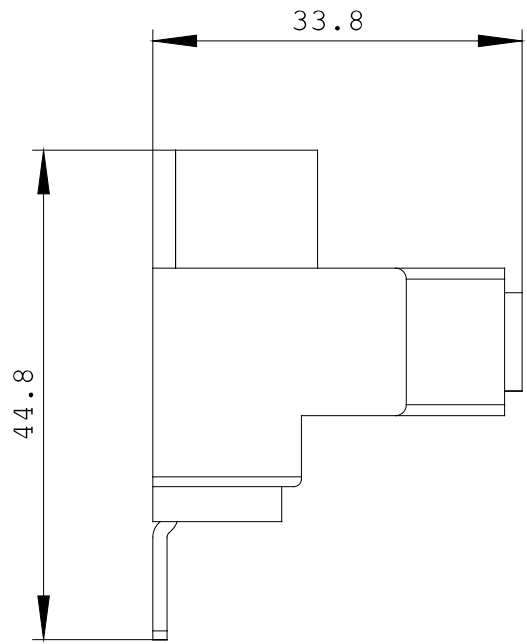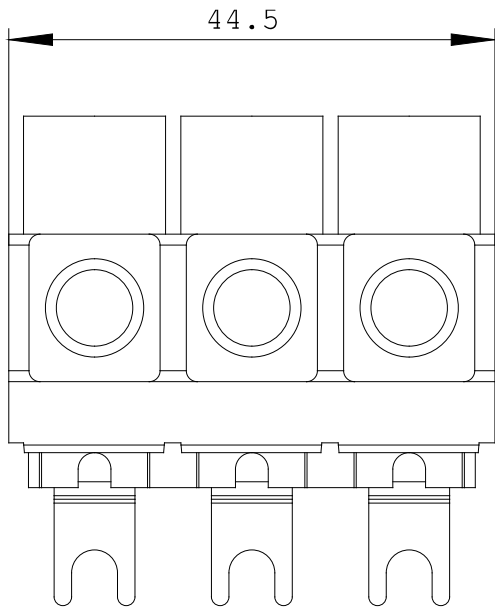

**last change:**

Feb 6, 2012