

# Actuator

45-  
2231.21N0.000

Distribution by  
Rs-online



<https://rs-online.eao.com/p/45-2231.21N0.000>

Your product:

---



## 45-2231.21N0.000 Actuator

### FRONT

Front dimension:	Ø 29,5 mm
Front form:	Round
Front bezel colour:	Silver
Front bezel material:	Metal

### MOUNTING

Design:	Raised
Mounting cut-out:	Ø 22.3 mm
Mounting type:	Panel mounting

### OPERATING-/INDICATION PART

Lens colour:	White
Lens material:	Plastic
Lens illumination:	Illuminated
Lens shape:	Flush
Lens optics:	transparent
Lens type:	Level with front bezel
Illumination colour:	White

### MECHANICAL CHARACTERISTIC

Switching action:	Momentary
Switching system:	Slow-make switching element

**Mechanical lifetime:** 3 Mil. cycles of operation

**Operating frequency:** Max. 3 600/h

**Weight:** 0.039 kg

## AMBIENT CONDITION

**IP front protection:** IP66, IP67, IP69K

**Operating temperature:** – 25 °C ... + 70 °C

**Storage temperature:** – 40 °C ... + 80 °C

**Shock resistance:** According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

**Vibration resistance:** According to IEC 60068-2-6: 20 ... 500 Hz: 5 g

**Climate resistance:** During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

## CERTIFICATE

**REACH:** REACH compliant

**RoHS:** RoHS compliant


## OTHER

**Short Description:** Actuator, Ø 22.3 mm, Ø 29,5 mm, Flush, Illuminated, White, Plastic, transparent, Round, Silver, Metal, Momentary, IP66, IP67, IP69K, White


**Housing colour:** Silver

**Housing material:** Metal

**Wiring diagrams:**

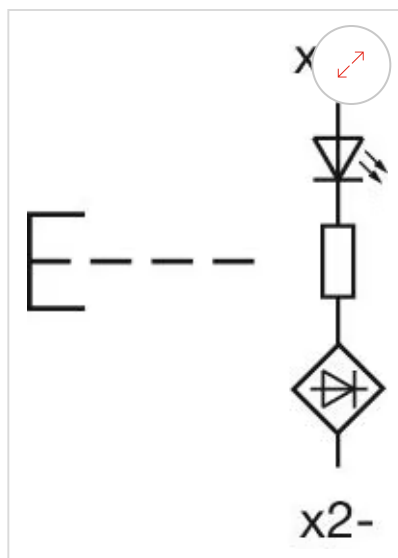

**Mounting cut-outs:**

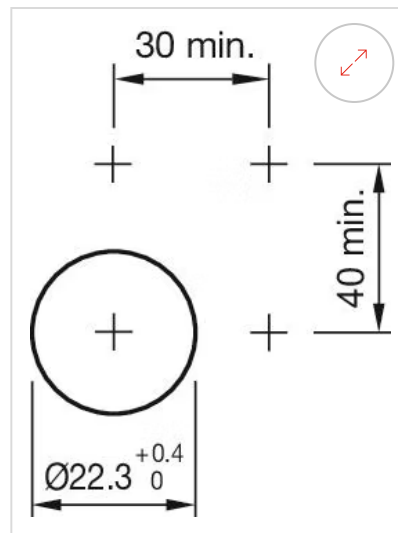

**Dimension drawings:**

