


C27, Film, Film/Foil Polypropylene, Motor Run, 1.5 uF, 5%, 470 VAC

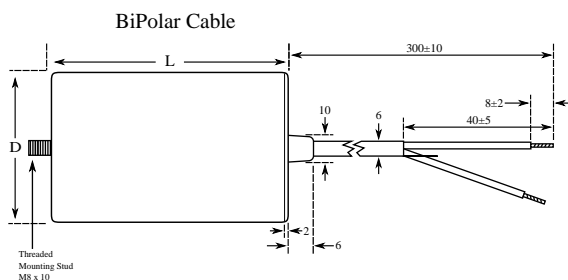

Dimensions	
D	25mm +1mm
L	58.5mm +/-2mm

Packaging Specifications	
Mounting:	Bolt - M8x13
Packaging:	Bulk, Bag
Packaging Quantity:	162

General Information	
Supplier:	KEMET
Series:	C27
Dielectric:	Film/Foil Polypropylene
Style:	Can
Description:	Plastic Case and Cover, Ultra Sonically Welded Seal
Features:	Ultra Sonically Welded Seal, Safety Class P0, UL_94 V0 Disk
RoHS:	Yes
Termination:	Tin Copper
Lead:	BiPolar Cables
Qualifications:	UL, VDE, UL (Construction Only), UL_94 V0 Disk

Specifications	
Capacitance:	1.5 uF
Capacitance Tolerance:	5%
Voltage AC:	470 VAC
Temperature Range:	-25/+85C
Rated Temperature:	85°C
Max dV/dt:	20 V/us