




Product Datasheet

KY 33A-03 WIRE 750V,20AWG 19/0.20mm TC



Cross Section:

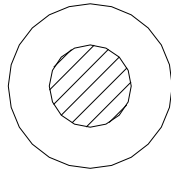

Characteristics:

Relevant Standards: NFC 93521 & NFC 32070/C1

Operating Voltage: 750 V

Operating Temperature (°C): -40 to 105 °C

Applications: These wires are mainly designed for internal wiring in electronic equipment.

Construction:

Inner Conductor: Tinned plated copper

Insulation: PVC

Marking: No

Specification:

Conductor				Overall Diameter (mm)		Conductor resistance (Ω/Km, at 20°C)	Mass
Size AWG	Area (mm ²)	O/D (mm)	Stranding (mm)	Min.	Max.	Max.	Average (Kg/Km)
20	0.60	1.00	19/ 0.20	2.20	2.50	36.7	9.8

Product Range:

RS Code

8513614

8513618

Description

KY33A-03 BLACK,100M/PAPER REEL

KY33A-03 WHITE,100M/PAPER REEL

RoHS ✓