


Flange Units (Square) UCF2

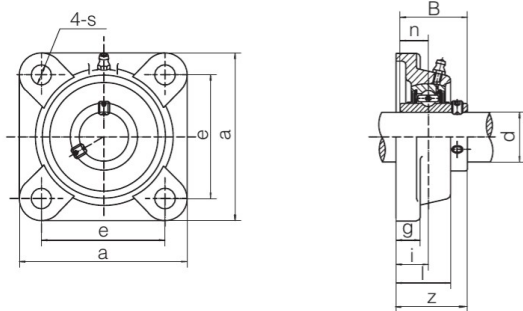

Unit number	Dimensions (mm)									
	d	a	e	i	g	l	s	z	B	n
UCF201D1	12	86	64	15	12	25.5	12	33.3	31	12.7
UCF202D1	15	86	64	15	12	25.5	12	33.3	31	12.7
UCF203D1	17	86	64	15	12	25.5	12	33.3	31	12.7
UCF204D1	20	86	64	15	12	25.5	12	33.3	31	12.7
UCF205D1	25	95	70	16	14	27	12	35.8	34.1	14.3
UCF206D1	30	108	83	18	14	31	12	40.2	38.1	15.9
UCF207D1	35	117	92	19	16	34	14	44.4	42.9	17.5
UCF208D1	40	130	102	21	16	36	16	51.2	49.2	19
UCF209D1	45	137	105	22	18	38	16	52.2	49.2	19
UCF210D1	50	143	111	22	18	40	16	54.6	51.6	19
UCF211D1	55	162	130	25	20	43	19	58.4	55.6	22.2
UCF212D1	60	175	143	29	20	48	19	68.7	65.1	25.4
UCF213D1	65	187	149	30	22	50	19	69.7	65.1	25.4
UCF214D1	70	193	152	31	22	54	19	75.4	74.6	30.2
UCF215D1	75	200	159	34	22	56	19	78.5	77.8	33.3
UCF216D1	80	208	165	34	22	58	23	83.3	82.6	33.3
UCF217D1	85	220	175	36	24	63	23	87.6	85.7	34.1
UCF218D1	90	235	187	40	24	68	23	96.3	96	39.7

Bolt size (mm)	Bearing number	Housing number	Weight (kg)
M10	UC201D1	F201D1	0.59
M10	UC202D1	F202D1	0.58
M10	UC203D1	F203D1	0.57
M10	UC204D1	F204D1	0.55
M10	UC205D1	F205D1	0.73
M10	UC206D1	F206D1	1.02
M12	UC207D1	F207D1	1.33
M14	UC208D1	F208D1	1.67
M14	UC209D1	F209D1	2.00
M14	UC210D1	F210D1	2.32
M16	UC211D1	F211D1	3.12
M16	UC212D1	F212D1	3.95
M16	UC213D1	F213D1	4.81
M16	UC214D1	F214D1	5.42
M16	UC215D1	F215D1	5.94
M20	UC216D1	F216D1	6.94
M20	UC217D1	F217D1	8.67
M20	UC218D1	F218D1	10.62