

Features

- High quality 3-pin SAA/3 AS3112 Plug for use in Australia and New Zealand
- Rubber cable type: H05RRF3G1.0- Flexible 2.5M Black
- IEC60320 C15/120 degrees C15M Universal connector female
- Integrated strain reliefs for high flexibility

RS PRO 2.5m Power Cable C15 to SAA/3 AS3112 10A-250 V

RS Stock No.: 0558965



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- RS Pro power cable assembly in black colour with length 2.5 meters. The product withstands current up to 10 Amps. This IEC cable assembly has a fully moulded SAA/3 AS3112 (AUS /NZ) plug on one and fully moulded C15M socket on the other end. The C15 IEC cord is designed for use in high temperature power applications such as Data- centres, server cabinets etc.

General Specifications

Connector A	C15M, IEC Straight female, EN /IEC 60320 /C15
Connector B	SAA/3 AS3112 PLUG
Power Cord Rating	10A- 250V
Sheath Colour	Black

Mechanical Specifications

Length	2.5 meters
--------	------------

Electrical Specifications

Power Cord Rating	10A- 250v
Visual Inspection	100%
Electrical Testing	100%
High pot test wire to wire	3.00Vac. for 2 sec.
Continuity Test	25Aac to grounding /20Aac to line and neutral
Polarity Test	Yes
Skin High Pot test	6:000 line to skin


Protection Category

Environmental Conformity	EU-Directive 2002/96/EC (WEEE)
	Eu-Directive 2003/11/EC (Council Directive 76/769/EEC)
	Eu-Directive 2002/95/EC (R

Approvals

C15M Connector	CE, UKCA, ENEC
SAA/3 AS3112 Plug	SAA
Cable	Harmonized <HAR>

Electrical Specifications

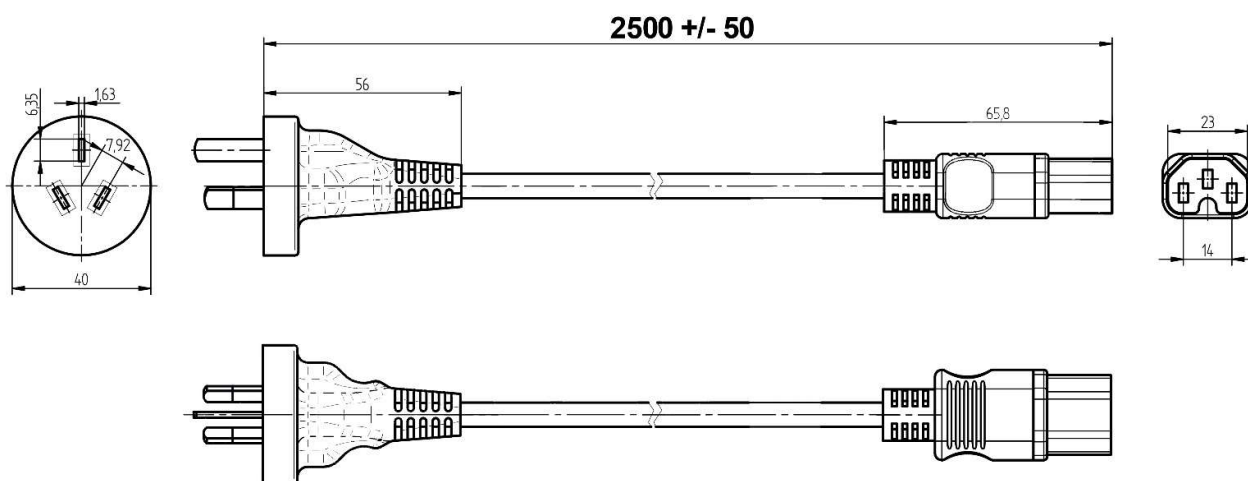

All dimensions in mm