




**Part Number :** [5037640401](#)

**Product Description :** 1.00mm Pitch, Pico-Lock Receptacle Crimp Housing, Single Row, Positive Lock, 4 Circuits, Black

**Series Number :** 503764

**Status :** Active

**Product Category :** Connector Housings

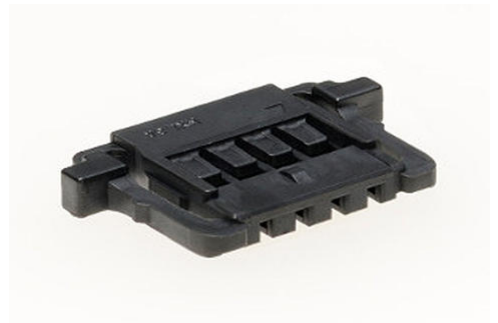

---

## Documents & Resources

### Drawings

[5037640401\\_sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[5037640401.dxf](#)

### Specifications

[AS-503764-001-001.pdf](#)

[SPK-503764-001-001.pdf](#)

[5037640000-PS-000.pdf](#)


[5037641001-PS-000.pdf](#)

[PS-503764-001-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)

EU RoHS	Compliant per EU 2015/863
---------	---------------------------

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### Substances of Interest

- PFAS

### EU RoHS Certificate of Compliance

### Additional Product Compliance Information

## Part Details

### General

Status	Active
Category	Connector Housings
Series	503764
Description	1.00mm Pitch, Pico-Lock Receptacle Crimp Housing, Single Row, Positive Lock, 4 Circuits, Black
Application	Signal, Wire-to-Board
Comments	See Molex product specification PS-503764-001 for additional current de-rating information
Product Name	Pico-Lock
UPC	887191353814

### Agency

UL	E29179
----	--------

### Physical

Circuits (maximum)	4
Color - Resin	Black

Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	High Temperature Thermoplastic
Net Weight	31.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
1.00mm Pitch Pico-Lock Right-Angle Single Row Headers	<u>503763</u>

### Use with Part(s)

Description	Part Number
1.00mm Pitch, Pico-Lock Female Crimp Terminals	<u>503765</u>