

適合ハーネス一覧

機種名	ハーネス型番	
	入力側	出力側
LCA10S	H-IN-4	H-OU-7
LCA15S	H-IN-4	H-OU-8
LCA30S		H-OU-9
LCA50S,※LGA50A	H-IN-5	H-OU-9
LCA75S,※LGA75A		H-OU-18
LCA100S,※LGA100A	または H-IN-10	H-OU-10
LCA150S ※LGA150A		H-OU-11
※LGA240A		H-OU-12
※LFA300F	H-IN-14	H-OU-11
SNA-01,-03	H-OU-8	H-OU-8
SNA-06	H-OU-9	H-OU-9
SNR-10	H-OU-18	H-OU-18

機種名	ハーネス型番	
	入力側	出力側
LDA10F		H-OU-8
LDA15F		H-OU-8
LDA30F,※LFA30F		H-OU-9
LDA50F,LEA50F,※LFA50F		H-OU-9
LDA75F,LEA75F,※LFA75F		H-OU-18
LDA100W,LEA100F,※LFA100F		H-OU-10
LEP100F,150F,240F		
LDA150W,LEA150F,※LFA150F ※LFA240F		H-OU-11
※LFA10F		H-OU-12
※LFA15F		H-OU-34
※LDA300W	H-IN-7	H-OU-22

※LDA300Wは-J仕様対応品(オプション)

※LGA50,75,100,150,240Aは-J1仕様対応品(オプション)

※LFA10,15,30,50,75,100,150,240,300Fは-J1仕様対応品(オプション)

標準価格

●型番 H-IN-4 ハウジング:XHP-7 [日本圧着端子] 接触子:SXH-001T-P0.6 [日本圧着端子]	●形状	●使用電線 <table border="1"><thead><tr><th>コネクタピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さl [mm]</th></tr></thead><tbody><tr><td>1</td><td>UL1007</td><td>22</td><td>黒</td><td>500</td></tr><tr><td>2, 3</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>4</td><td>UL1007</td><td>22</td><td>白</td><td>500</td></tr><tr><td>5, 6</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>7</td><td>UL1007</td><td>22</td><td>緑</td><td>500</td></tr></tbody></table>	コネクタピン番号	電線番号	AWG	色	長さl [mm]	1	UL1007	22	黒	500	2, 3	あきピン				4	UL1007	22	白	500	5, 6	あきピン				7	UL1007	22	緑	500	¥200
コネクタピン番号	電線番号	AWG	色	長さl [mm]																													
1	UL1007	22	黒	500																													
2, 3	あきピン																																
4	UL1007	22	白	500																													
5, 6	あきピン																																
7	UL1007	22	緑	500																													
●型番 H-IN-5 ハウジング:VHR-5N [日本圧着端子] 接触子:SVH-21T-P1.1 [日本圧着端子]	●形状	●使用電線 <table border="1"><thead><tr><th>コネクタピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さl [mm]</th></tr></thead><tbody><tr><td>1</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr><tr><td>2</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>3</td><td>UL1015</td><td>18</td><td>白</td><td>500</td></tr><tr><td>4</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>5</td><td>UL1015</td><td>18</td><td>緑</td><td>500</td></tr></tbody></table>	コネクタピン番号	電線番号	AWG	色	長さl [mm]	1	UL1015	18	黒	500	2	あきピン				3	UL1015	18	白	500	4	あきピン				5	UL1015	18	緑	500	¥200
コネクタピン番号	電線番号	AWG	色	長さl [mm]																													
1	UL1015	18	黒	500																													
2	あきピン																																
3	UL1015	18	白	500																													
4	あきピン																																
5	UL1015	18	緑	500																													
●型番 H-IN-7 ハウジング:1-178128-5 [Tyco Electronics] 接触子:1-175218-2 または1-175218-3 [Tyco Electronics]	●形状	●使用電線 <table border="1"><thead><tr><th>コネクタピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さl [mm]</th></tr></thead><tbody><tr><td>1</td><td>UL1015</td><td>18</td><td>白</td><td>500</td></tr><tr><td>2</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>3</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr><tr><td>4</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>5</td><td>UL1015</td><td>18</td><td>黄緑/黒 スピアラル</td><td>500</td></tr></tbody></table>	コネクタピン番号	電線番号	AWG	色	長さl [mm]	1	UL1015	18	白	500	2	あきピン				3	UL1015	18	黒	500	4	あきピン				5	UL1015	18	黄緑/黒 スピアラル	500	¥500
コネクタピン番号	電線番号	AWG	色	長さl [mm]																													
1	UL1015	18	白	500																													
2	あきピン																																
3	UL1015	18	黒	500																													
4	あきピン																																
5	UL1015	18	黄緑/黒 スピアラル	500																													
●型番 H-IN-10 ハウジング:VHR-5N [日本圧着端子] 接触子:SVH-21T-P1.1 [日本圧着端子]	●形状	●使用電線 <table border="1"><thead><tr><th>コネクタピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さl [mm]</th></tr></thead><tbody><tr><td>1</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr><tr><td>2</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>3</td><td>UL1015</td><td>18</td><td>白</td><td>500</td></tr><tr><td>4</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>5</td><td>UL1015</td><td>18</td><td>黄緑/黒 スピアラル</td><td>500</td></tr></tbody></table>	コネクタピン番号	電線番号	AWG	色	長さl [mm]	1	UL1015	18	黒	500	2	あきピン				3	UL1015	18	白	500	4	あきピン				5	UL1015	18	黄緑/黒 スピアラル	500	¥200
コネクタピン番号	電線番号	AWG	色	長さl [mm]																													
1	UL1015	18	黒	500																													
2	あきピン																																
3	UL1015	18	白	500																													
4	あきピン																																
5	UL1015	18	黄緑/黒 スピアラル	500																													
●型番 H-IN-14 ハウジング:VHR-8N [日本圧着端子] 接触子:SVH-21T-P1.1 [日本圧着端子]	●形状	●使用電線 <table border="1"><thead><tr><th>コネクタピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さl [mm]</th></tr></thead><tbody><tr><td>1, 2</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr><tr><td>3</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>4, 5</td><td>UL1015</td><td>18</td><td>白</td><td>500</td></tr><tr><td>6</td><td>あきピン</td><td></td><td></td><td></td></tr><tr><td>7, 8</td><td>UL1015</td><td>18</td><td>緑</td><td>500</td></tr></tbody></table>	コネクタピン番号	電線番号	AWG	色	長さl [mm]	1, 2	UL1015	18	黒	500	3	あきピン				4, 5	UL1015	18	白	500	6	あきピン				7, 8	UL1015	18	緑	500	¥560
コネクタピン番号	電線番号	AWG	色	長さl [mm]																													
1, 2	UL1015	18	黒	500																													
3	あきピン																																
4, 5	UL1015	18	白	500																													
6	あきピン																																
7, 8	UL1015	18	緑	500																													
●型番 H-OU-7 ハウジング:XHP-2 [日本圧着端子] 接触子:SXH-001T-P0.6 [日本圧着端子]	●形状	●使用電線 <table border="1"><thead><tr><th>コネクタピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さl [mm]</th></tr></thead><tbody><tr><td>1</td><td>UL1007</td><td>22</td><td>黒</td><td>500</td></tr><tr><td>2</td><td>UL1007</td><td>22</td><td>赤</td><td>500</td></tr></tbody></table>	コネクタピン番号	電線番号	AWG	色	長さl [mm]	1	UL1007	22	黒	500	2	UL1007	22	赤	500	¥200															
コネクタピン番号	電線番号	AWG	色	長さl [mm]																													
1	UL1007	22	黒	500																													
2	UL1007	22	赤	500																													
●型番 H-OU-8 ハウジング:XHP-4 [日本圧着端子] 接触子:SXH-001T-P0.6 [日本圧着端子]	●形状	●使用電線 <table border="1"><thead><tr><th>コネクタピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さl [mm]</th></tr></thead><tbody><tr><td>1</td><td>UL1007</td><td>22</td><td>黒</td><td>500</td></tr><tr><td>2</td><td>UL1007</td><td>22</td><td>黒</td><td>500</td></tr><tr><td>3</td><td>UL1007</td><td>22</td><td>赤</td><td>500</td></tr><tr><td>4</td><td>UL1007</td><td>22</td><td>赤</td><td>500</td></tr></tbody></table>	コネクタピン番号	電線番号	AWG	色	長さl [mm]	1	UL1007	22	黒	500	2	UL1007	22	黒	500	3	UL1007	22	赤	500	4	UL1007	22	赤	500	¥200					
コネクタピン番号	電線番号	AWG	色	長さl [mm]																													
1	UL1007	22	黒	500																													
2	UL1007	22	黒	500																													
3	UL1007	22	赤	500																													
4	UL1007	22	赤	500																													

Option

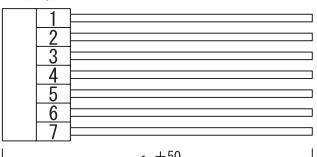
 
●型番	●形状	●使用電線	標準価格																									
H-OU-9 ハウジング：VHR-4N [日本圧着端子] 接触子：SVH-21T-P1.1 [日本圧着端子]		<table border="1"> <thead> <tr> <th>コネクタ ピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さ <i>l</i> [mm]</th></tr> </thead> <tbody> <tr> <td>1</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr> <tr> <td>2</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr> <tr> <td>3</td><td>UL1015</td><td>18</td><td>赤</td><td>500</td></tr> <tr> <td>4</td><td>UL1015</td><td>18</td><td>赤</td><td>500</td></tr> </tbody> </table>	コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1	UL1015	18	黒	500	2	UL1015	18	黒	500	3	UL1015	18	赤	500	4	UL1015	18	赤	500	¥200
コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																								
1	UL1015	18	黒	500																								
2	UL1015	18	黒	500																								
3	UL1015	18	赤	500																								
4	UL1015	18	赤	500																								
H-OU-10 ハウジング：VHR-8N [日本圧着端子] 接触子：SVH-21T-P1.1 [日本圧着端子]		<table border="1"> <thead> <tr> <th>コネクタ ピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さ <i>l</i> [mm]</th></tr> </thead> <tbody> <tr> <td>1~4</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr> <tr> <td>5~8</td><td>UL1015</td><td>18</td><td>赤</td><td>500</td></tr> </tbody> </table>	コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1~4	UL1015	18	黒	500	5~8	UL1015	18	赤	500	¥500										
コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																								
1~4	UL1015	18	黒	500																								
5~8	UL1015	18	赤	500																								
H-OU-11 ハウジング：VHR-6N [日本圧着端子] 接触子：SVH-21T-P1.1 [日本圧着端子]		<table border="1"> <thead> <tr> <th>コネクタ ピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さ <i>l</i> [mm]</th></tr> </thead> <tbody> <tr> <td>1~6</td><td>UL1015</td><td>18</td><td>赤</td><td>500</td></tr> </tbody> </table>	コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1~6	UL1015	18	赤	500	¥400															
コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																								
1~6	UL1015	18	赤	500																								
H-OU-12 ハウジング：VHR-7N [日本圧着端子] 接触子：SVH-21T-P1.1 [日本圧着端子]		<table border="1"> <thead> <tr> <th>コネクタ ピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さ <i>l</i> [mm]</th></tr> </thead> <tbody> <tr> <td>1~7</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr> </tbody> </table>	コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1~7	UL1015	18	黒	500	¥400															
コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																								
1~7	UL1015	18	黒	500																								
H-OU-18 ハウジング：VHR-6N [日本圧着端子] 接触子：SVH-21T-P1.1 [日本圧着端子]		<table border="1"> <thead> <tr> <th>コネクタ ピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さ <i>l</i> [mm]</th></tr> </thead> <tbody> <tr> <td>1~3</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr> <tr> <td>4~6</td><td>UL1015</td><td>18</td><td>赤</td><td>500</td></tr> </tbody> </table>	コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1~3	UL1015	18	黒	500	4~6	UL1015	18	赤	500	¥400										
コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																								
1~3	UL1015	18	黒	500																								
4~6	UL1015	18	赤	500																								
H-OU-22 ハウジング：1-178288-8 [Tyco Electronics] 接触子：1-175218-2 または1-175218-3 [Tyco Electronics]		<table border="1"> <thead> <tr> <th>コネクタ ピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さ <i>l</i> [mm]</th></tr> </thead> <tbody> <tr> <td>1~5</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr> <tr> <td>6~10</td><td>UL1015</td><td>18</td><td>赤</td><td>500</td></tr> </tbody> </table>	コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1~5	UL1015	18	黒	500	6~10	UL1015	18	赤	500	¥900										
コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																								
1~5	UL1015	18	黒	500																								
6~10	UL1015	18	赤	500																								
H-OU-34 ハウジング：VHR-2N [日本圧着端子] 接触子：SVH-21T-P1.1 [日本圧着端子]		<table border="1"> <thead> <tr> <th>コネクタ ピン番号</th><th>電線番号</th><th>AWG</th><th>色</th><th>長さ <i>l</i> [mm]</th></tr> </thead> <tbody> <tr> <td>1</td><td>UL1015</td><td>18</td><td>黒</td><td>500</td></tr> <tr> <td>2</td><td>UL1015</td><td>18</td><td>赤</td><td>500</td></tr> </tbody> </table>	コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1	UL1015	18	黒	500	2	UL1015	18	赤	500	¥200										
コネクタ ピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																								
1	UL1015	18	黒	500																								
2	UL1015	18	赤	500																								

適合ハーネス一覧

機種名	ハーネス型番	
	入力側	出力側
LFA10F	H-IN-12	H-OU-33
LFA15F		H-OU-33
LFA30F		H-OU-28
LFA50F, LGA50A		H-OU-28
LFA75F, LGA75A		H-OU-29
LFA100F, LGA100A		H-OU-30
LFA150F, LGA150A, LFA240F		H-OU-31 H-OU-32
LGA240A, LFA300F	H-IN-13	H-OU-31 H-OU-32

LGAシリーズ
LFAシリーズ

●型番	●形状	●使用電線	標準価格																														
H-IN-12 ハウジング : 1-1123722-5 (Tyco Electronics) 接触子 : 1123721-1 または1318912-1 (Tyco Electronics)		<table border="1"> <thead> <tr> <th>コネクタピン番号</th> <th>電線番号</th> <th>AWG</th> <th>色</th> <th>長さ <i>l</i> [mm]</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>黒</td> <td>500</td> </tr> <tr> <td>2</td> <td>あきピン</td> <td></td> <td></td> <td></td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>白</td> <td>500</td> </tr> <tr> <td>4</td> <td>あきピン</td> <td></td> <td></td> <td></td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>緑</td> <td>500</td> </tr> </tbody> </table>	コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1	UL1015	18	黒	500	2	あきピン				3	UL1015	18	白	500	4	あきピン				5	UL1015	18	緑	500	¥290
コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																													
1	UL1015	18	黒	500																													
2	あきピン																																
3	UL1015	18	白	500																													
4	あきピン																																
5	UL1015	18	緑	500																													
H-IN-13 ハウジング : 1-1123722-8 (Tyco Electronics) 接触子 : 1123721-1 または1318912-1 (Tyco Electronics)		<table border="1"> <thead> <tr> <th>コネクタピン番号</th> <th>電線番号</th> <th>AWG</th> <th>色</th> <th>長さ <i>l</i> [mm]</th> </tr> </thead> <tbody> <tr> <td>1, 2</td> <td>UL1015</td> <td>18</td> <td>黒</td> <td>500</td> </tr> <tr> <td>3</td> <td>あきピン</td> <td></td> <td></td> <td></td> </tr> <tr> <td>4, 5</td> <td>UL1015</td> <td>18</td> <td>白</td> <td>500</td> </tr> <tr> <td>6</td> <td>あきピン</td> <td></td> <td></td> <td></td> </tr> <tr> <td>7, 8</td> <td>UL1015</td> <td>18</td> <td>緑</td> <td>500</td> </tr> </tbody> </table>	コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1, 2	UL1015	18	黒	500	3	あきピン				4, 5	UL1015	18	白	500	6	あきピン				7, 8	UL1015	18	緑	500	¥560
コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																													
1, 2	UL1015	18	黒	500																													
3	あきピン																																
4, 5	UL1015	18	白	500																													
6	あきピン																																
7, 8	UL1015	18	緑	500																													
H-OU-28 ハウジング : 1-1123722-4 (Tyco Electronics) 接触子 : 1123721-1 または1318912-1 (Tyco Electronics)		<table border="1"> <thead> <tr> <th>コネクタピン番号</th> <th>電線番号</th> <th>AWG</th> <th>色</th> <th>長さ <i>l</i> [mm]</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>黒</td> <td>500</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>黒</td> <td>500</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>赤</td> <td>500</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>赤</td> <td>500</td> </tr> </tbody> </table>	コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1	UL1015	18	黒	500	2	UL1015	18	黒	500	3	UL1015	18	赤	500	4	UL1015	18	赤	500	¥360					
コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																													
1	UL1015	18	黒	500																													
2	UL1015	18	黒	500																													
3	UL1015	18	赤	500																													
4	UL1015	18	赤	500																													
H-OU-29 ハウジング : 1-1123722-6 (Tyco Electronics) 接触子 : 1123721-1 または1318912-1 (Tyco Electronics)		<table border="1"> <thead> <tr> <th>コネクタピン番号</th> <th>電線番号</th> <th>AWG</th> <th>色</th> <th>長さ <i>l</i> [mm]</th> </tr> </thead> <tbody> <tr> <td>1~3</td> <td>UL1015</td> <td>18</td> <td>黒</td> <td>500</td> </tr> <tr> <td>4~6</td> <td>UL1015</td> <td>18</td> <td>赤</td> <td>500</td> </tr> </tbody> </table>	コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1~3	UL1015	18	黒	500	4~6	UL1015	18	赤	500	¥510															
コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																													
1~3	UL1015	18	黒	500																													
4~6	UL1015	18	赤	500																													
H-OU-30 ハウジング : 1-1123722-8 (Tyco Electronics) 接触子 : 1123721-1 または1318912-1 (Tyco Electronics)		<table border="1"> <thead> <tr> <th>コネクタピン番号</th> <th>電線番号</th> <th>AWG</th> <th>色</th> <th>長さ <i>l</i> [mm]</th> </tr> </thead> <tbody> <tr> <td>1~4</td> <td>UL1015</td> <td>18</td> <td>黒</td> <td>500</td> </tr> <tr> <td>5~8</td> <td>UL1015</td> <td>18</td> <td>赤</td> <td>500</td> </tr> </tbody> </table>	コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1~4	UL1015	18	黒	500	5~8	UL1015	18	赤	500	¥670															
コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																													
1~4	UL1015	18	黒	500																													
5~8	UL1015	18	赤	500																													
H-OU-31 ハウジング : 1-1123722-6 (Tyco Electronics) 接触子 : 1123721-1 または1318912-1 (Tyco Electronics)		<table border="1"> <thead> <tr> <th>コネクタピン番号</th> <th>電線番号</th> <th>AWG</th> <th>色</th> <th>長さ <i>l</i> [mm]</th> </tr> </thead> <tbody> <tr> <td>1~6</td> <td>UL1015</td> <td>18</td> <td>赤</td> <td>500</td> </tr> </tbody> </table>	コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]	1~6	UL1015	18	赤	500	¥510																				
コネクタピン番号	電線番号	AWG	色	長さ <i>l</i> [mm]																													
1~6	UL1015	18	赤	500																													

							標準価格
●型番	●形状	●使用電線					
H-OU-32		コネクタ ピン番号	電線番号	AWG	色	長さ ℓ [mm]	
ハウジング : 1-1123722-7 (Tyco Electronics)		1~7	UL1015	18	黒	500	¥590
接 触 子 : 1123721-1 または1318912-1 (Tyco Electronics)							
H-OU-33		コネクタ ピン番号	電線番号	AWG	色	長さ ℓ [mm]	
ハウジング : 1-1123722-2 (Tyco Electronics)		1	UL1015	18	黒	500	¥200
接 触 子 : 1123721-1 または1318912-1 (Tyco Electronics)		2	UL1015	18	赤	500	