 



suction cup VAS-15-1/8-SI-B

Part number: 1376604
☆ Core product range

FESTO

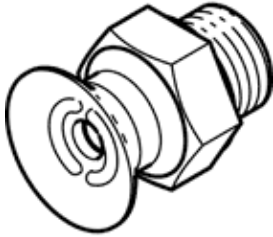

Data sheet

Feature	Value
Suction cup height compensator	1.2 mm
Nominal size	3 mm
suction cup diameter	15 mm
suction cup volume	0.328 cm ³
Position of connection	on top
Assembly position	Any
Suction cup shape	round flat
Operating pressure	-0.95 ... 0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-40 ... 200 °C
Retention force at nominal operating pressure	8.5 N
Product weight	4 g
Mounting type	Via vacuum port
Vacuum connection	G1/8
Colour	transparent
Shore hardness	60 +/- 5
Material of threaded plug	Wrought Aluminium alloy
Materials note	Contains PWIS substances Conforms to RoHS
Material suction cup	VMQ (silicon)